

UNIVERSAL CONTACTOR SUPPRESSOR



RC, 230VAC/DC/20VA/W

Art.No.: 20683  
Weight: 0.013  
Country of origin: CZ  
Model designation: RCF 22-470/230

230 V AC/DC  
RC  
For other configurations and voltages, please inquire.

Link to Product

Illustration

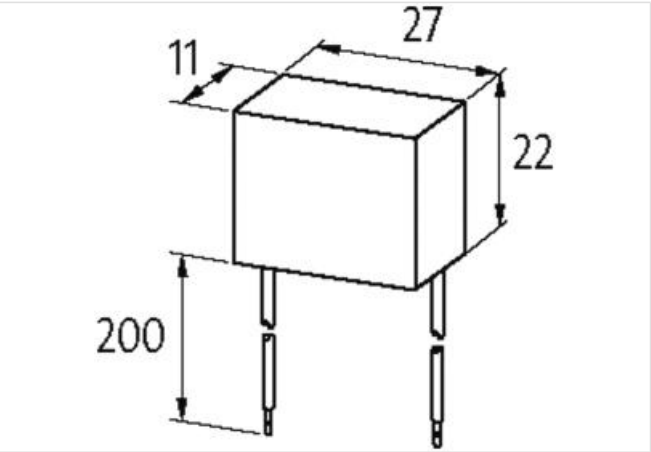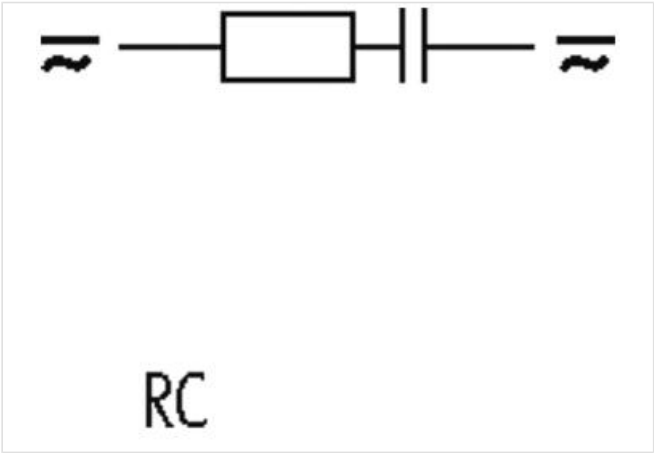

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |

|                       |               |
|-----------------------|---------------|
| ECLASS-9.0            | 27371013      |
| ECLASS-10.1           | 27371013      |
| ECLASS-11.1           | 27371013      |
| ECLASS-12.0           | 27371013      |
| ETIM-5.0              | EC002498      |
| customs tariff number | 85363010      |
| customs tariff number | 85363010      |
| GTIN                  | 4048879020336 |
| GTIN                  | 4048879020336 |
| Packaging unit        | 1             |
| Packaging unit        | 1             |

#### Compatibility | Compatible with

|                        |           |
|------------------------|-----------|
| Appropriate contactors | universal |
|------------------------|-----------|

#### Electrical data

|                    |         |
|--------------------|---------|
| Damping factor     | 1.5× UN |
| Holding power max. | 20 W    |

#### Electrical data | Input

|                       |       |
|-----------------------|-------|
| Input voltage AC min. | 110 V |
| Input voltage AC max. | 250 V |
| Input voltage DC min. | 110 V |
| Input voltage DC max. | 250 V |

#### Installation | Connection

|                        |                           |
|------------------------|---------------------------|
| Connection information | flexible connection wires |
|------------------------|---------------------------|

#### Device protection | Media

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

#### Mechanical data | Material data

|                                     |         |
|-------------------------------------|---------|
| Material housing                    | Plastic |
| Combustibility class housing (UL94) | V-0     |

#### Mechanical data | Mounting data

|        |       |
|--------|-------|
| Height | 22 mm |
| Width  | 27 mm |
| Depth  | 11 mm |

#### Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C  |