

UNIVERSAL CONTACTOR SUPPRESSOR



RC, 230VAC/DC/50VA/W

Art.No.: 20687  
Weight: 0.025  
Country of origin: CZ  
Model designation: RCF 68-100/230

300 V AC/DC  
RC  
For other configurations and voltages, please inquire.

Link to Product

Illustration

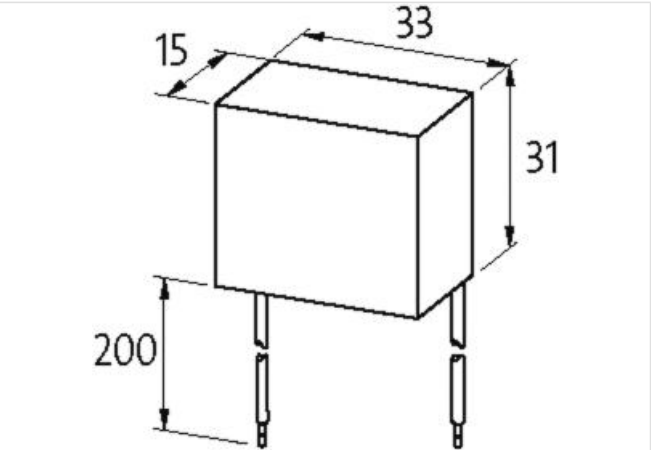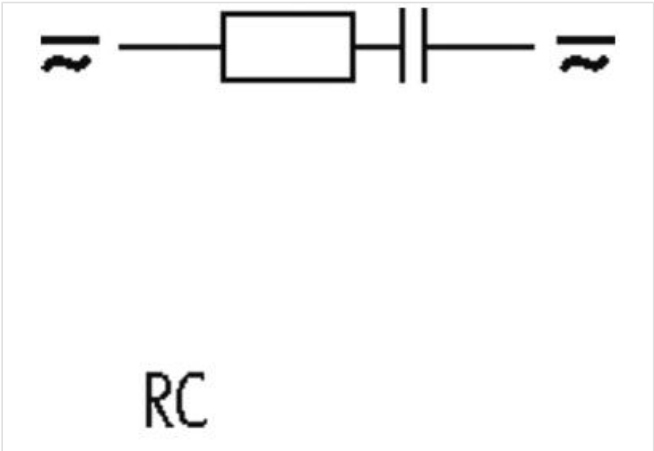

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
customs tariff number	85363010
GTIN	4048879020312
GTIN	4048879020312
Packaging unit	1
Packaging unit	1

#### Compatibility | Compatible with

Appropriate contactors	universal
------------------------	-----------

#### Electrical data

Damping factor	1.5× UN
Holding power max.	50 W

#### Electrical data | Input

Input voltage AC min.	110 V
Input voltage AC max.	250 V
Input voltage DC min.	110 V
Input voltage DC max.	250 V

#### Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

#### Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

#### Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

#### Mechanical data | Mounting data

Height	22 mm
Width	27 mm
Depth	11 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C