

MOTOR SUPPRESSOR

Varistor, 3x400VAC/20kW

Art.No.: 23118

Weight: 0.042

Country of origin: CZ

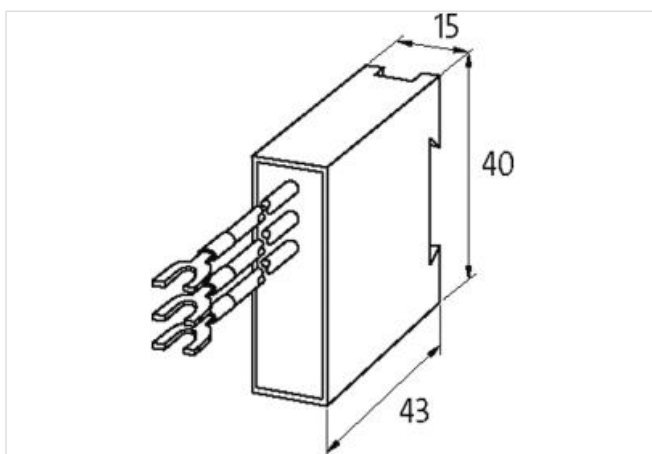
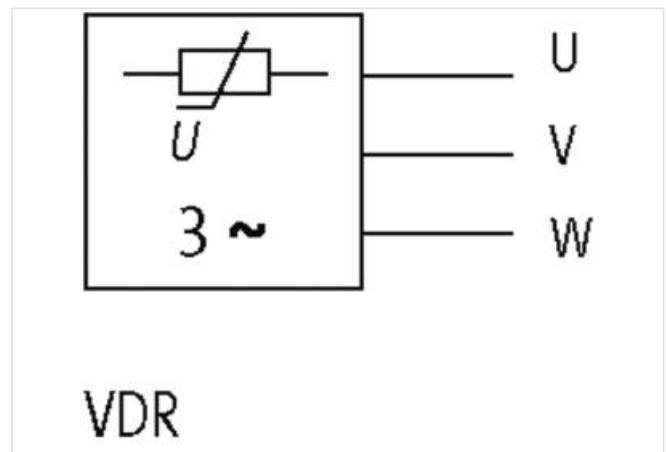
Model designation: VDR 3-400V-20KW

3× 400 V AC

VDR

For DIN-rail mounting use Art.-No. 20900 adapter feet

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0

27371013

ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000683
customs tariff number	85363010
customs tariff number	85363010
GTIN	4048879019255
GTIN	4048879019255
Packaging unit	1
Packaging unit	1
Electrical data Supply	
Power frequency	10 ... 400 Hz
Electrical data Input	
Input voltage AC	400 V
Installation	
Connection cross-section stranded/fine-stranded min.	0,35 mm²
Installation Connection	
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4
Length single strands	200 mm
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	43 mm
Width	15 mm
Depth	40 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C