

MOTOR SUPPRESSOR

Varistor, 3x400VAC/20kW

Art.No.: 23144  
Weight: 0.075  
Country of origin: CZ  
Model designation: RC 3 RG-400/20-M20 X 1,5 M6



3× 400 V AC

VDR

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

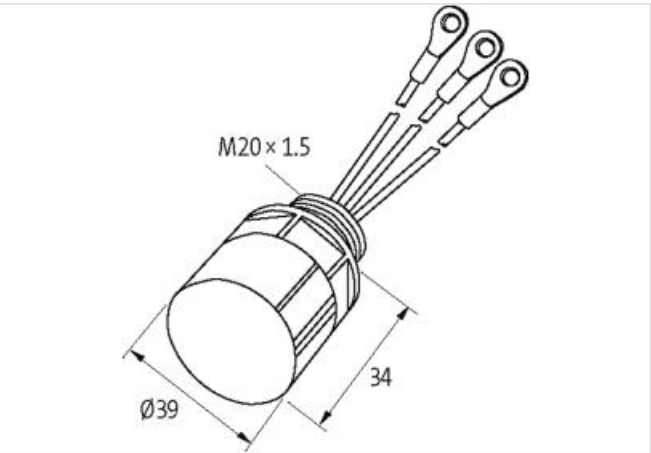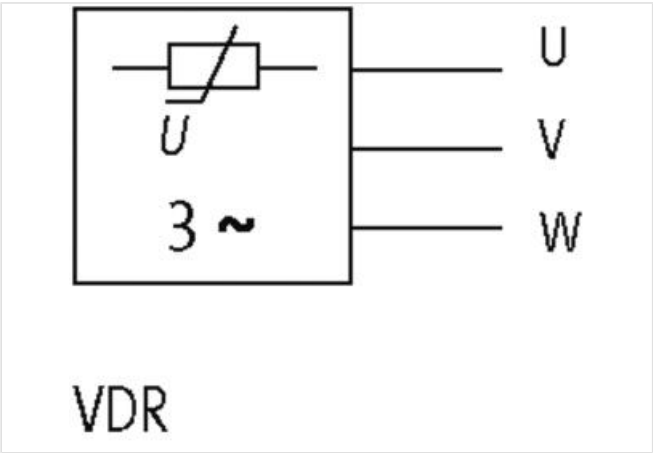

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013

ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000683
customs tariff number	85363010
customs tariff number	85363010
GTIN	4048879019118
GTIN	4048879019118
Packaging unit	1
Packaging unit	1

#### Electrical data | Input

Input voltage AC	400 V
------------------	-------

#### Installation

Connection cross section max.	1 mm <sup>2</sup>
-------------------------------	-------------------

#### Installation | Connection

Connection information	Single strands
Length single strands	150 mm
Ring terminals	M6isolated

#### Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

#### Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

#### Mechanical data | Mounting data

Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	39 mm
Width	39 mm
Depth	44 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C