

## MOTOR SUPPRESSOR

Varistor, 3x400VAC/4kW

Art.No.: 23170

Weight: 0.058

Country of origin: CZ

Model designation: RC 3R-400/4-M16 X 1,5 RKS-M6

3 × 400 V AC



VDR

isolated M6

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

### [Link to Product](#)

#### Illustration

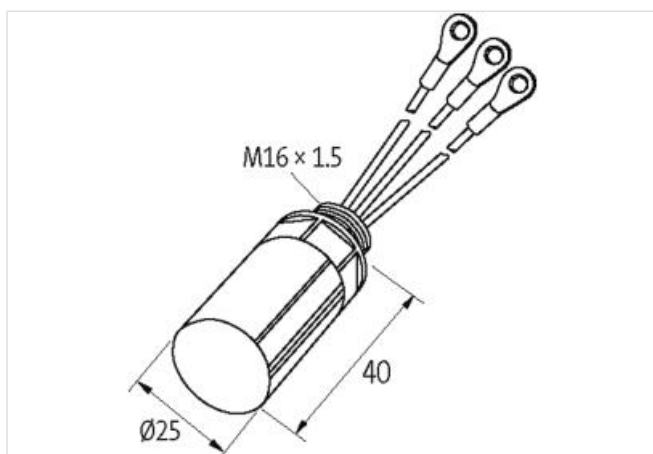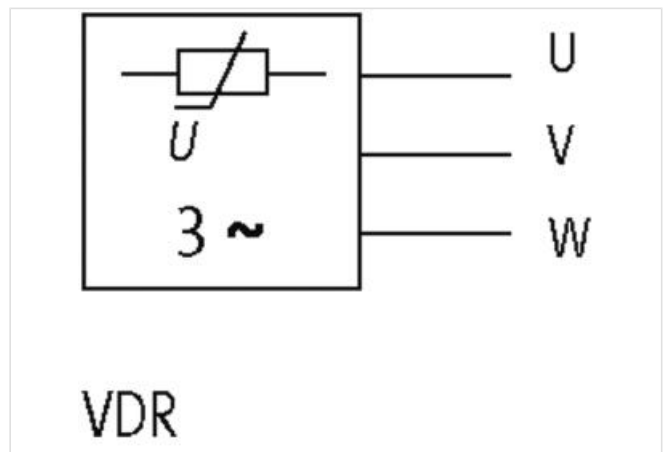

Product may differ from Image



#### Commercial data

ECLASS-6.0

27371013

ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000683
customs tariff number	85363010
customs tariff number	85363010
GTIN	4048879018937
GTIN	4048879018937
Packaging unit	1
Packaging unit	1
<b>Electrical data   Supply</b>	
Power frequency	10 ... 400 Hz
<b>Electrical data   Input</b>	
Input voltage AC	400 V
<b>Installation</b>	
Connection cross section max.	0,5 mm <sup>2</sup>
<b>Installation   Connection</b>	
Connection information	Single strands
Length single strands	100 mm
Ring terminals	M6isolated
<b>Device protection   Media</b>	
Flame resistance	flame retardant
<b>Mechanical data   Material data</b>	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
<b>Mechanical data   Mounting data</b>	
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	25 mm
Width	25 mm
Depth	40 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C