

**SUPPRESSOR FOR CONTACTORS**

VDR, 48 VAC/DC, 70 VA/W

Art.No.: 26181  
Weight: 0.014  
Country of origin: CZ  
Model designation: VG-A / 48



48 V AC/DC

VDR

For other configurations and voltages, please inquire.

**Link to Product**

**Illustration**

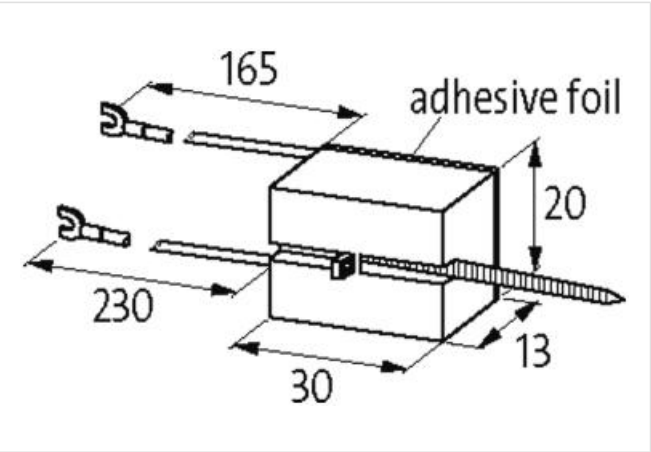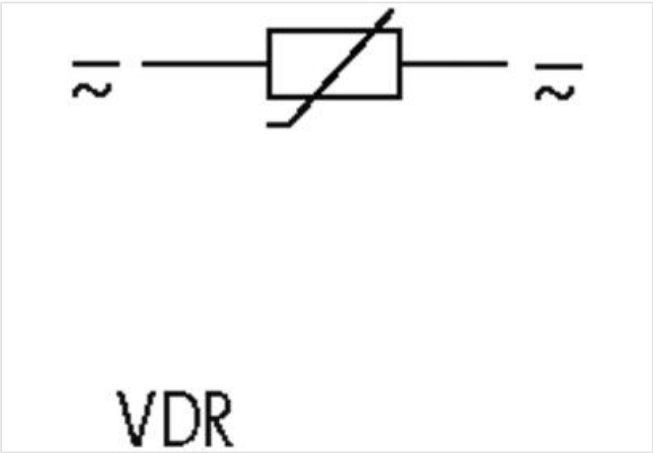

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
customs tariff number	85363010
GTIN	4048879018159
GTIN	4048879018159
Packaging unit	1
Packaging unit	1

#### Compatibility | Compatible with

Appropriate contactors	universal
------------------------	-----------

#### Electrical data

Damping factor	1.5× UN
Holding power max.	70 W

#### Electrical data | Input

Input voltage AC min.	24 V
Input voltage AC max.	48 V
Input voltage DC min.	24 V
Input voltage DC max.	48 V

#### Installation | Connection

Connection information	self-securing cable forks
------------------------	---------------------------

#### Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

#### Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

#### Mechanical data | Mounting data

Height	30 mm
Width	20 mm
Depth	13 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C