

**SUPPRESSOR FOR SIEMENS CONTACTOR**



Diode combination, 24 VDC, 10 W

Art.No.: 26521  
Weight: 0.01  
Country of origin: CZ  
Model designation: LG 24 VDC

24 V AC/DC  
Diode

**Link to Product**

**Illustration**

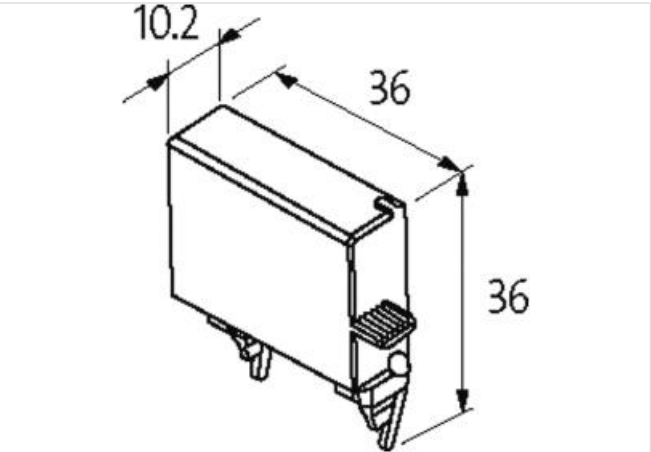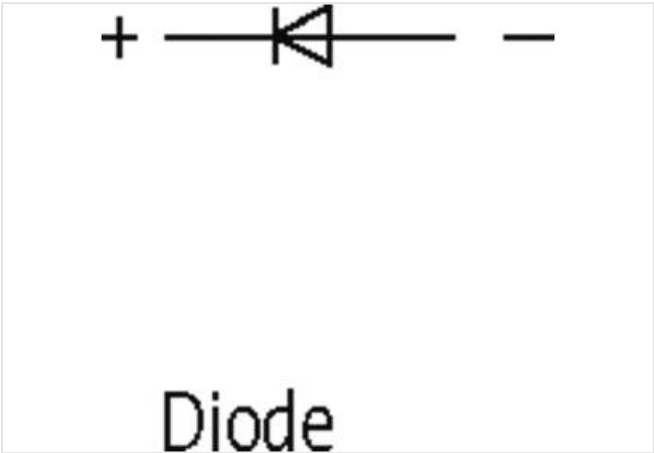

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
customs tariff number	85363010
GTIN	4048879017541
GTIN	4048879017541
Packaging unit	1
Packaging unit	1

#### Compatibility | Compatible with

Appropriate contactors	3 RT 1.3/1.4
------------------------	--------------

#### Electrical data

Damping factor	1.5× UN
----------------	---------

#### Electrical data | Input

Input voltage DC min.	0 V
Input voltage DC max.	30 V

#### Installation | Connection

Connection information	Plug contact
------------------------	--------------

#### Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

#### Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

#### Mechanical data | Mounting data

Height	36 mm
Width	10,2 mm
Depth	36 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C