

MASI67 INSTALLATION TECHNOLOGY

Distribution 1x profile- to 3x profile cable

Art.No.: 55034

Weight: 0.122

Country of origin: DE


Model designation: MASI67 Vert. 1x auf 3x Profilkabel

MASI67 distribution boxes


1 x on 3 x profile cable

[Link to Product](#)

Illustration

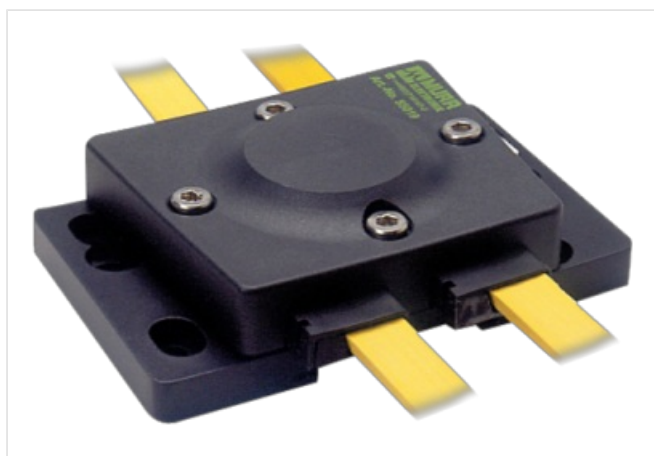

Product may differ from Image

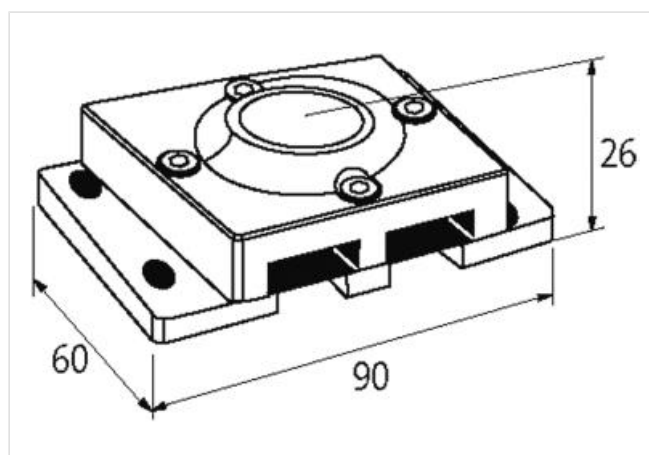

Commercial data

ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
customs tariff number	85369010
customs tariff number	85369010
GTIN	4048879052177
GTIN	4048879052177
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Operating voltage DC max.	36 V
Total current max.	8 A

Device protection | Electrical

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2025-05-09

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Insulation strength ASI/Power	200 V
-------------------------------	-------

Mechanical data | Mounting data

Mounting method	screwed, geschnappt
-----------------	---------------------

Suitable for mounting type	mounting rail, (EN 60715)
----------------------------	---------------------------

Height	90 mm
--------	-------

Width	74 mm
-------	-------

Depth	26 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	60 °C
----------------------------	-------

Storage temperature min.	-40 °C
--------------------------	--------

Storage temperature max.	80 °C
--------------------------	-------

Conformity

Product standard	EN 60664-1
------------------	------------