

MASI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to 7/8" female

Art.No.: 55035

Weight: 1.109

Country of origin: DE

Model designation: MASI67 Umsetzer 2x Profilk.7/8"Bu



MASI67 converter

2x profile cable to 7/8" (female)

Connection cables are in the online shop under "Connection Technology".

[Link to Product](#)

Illustration

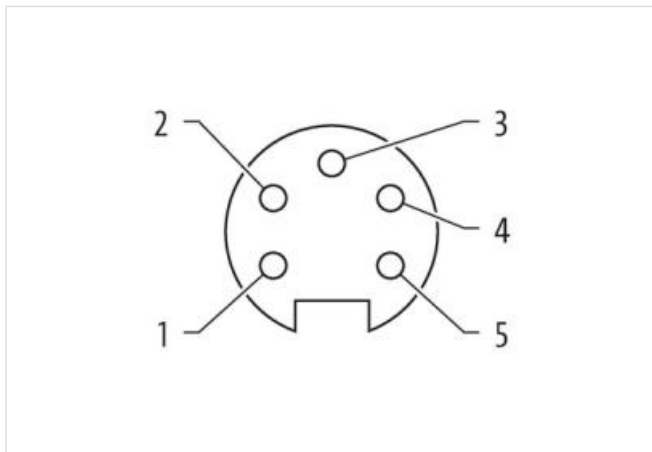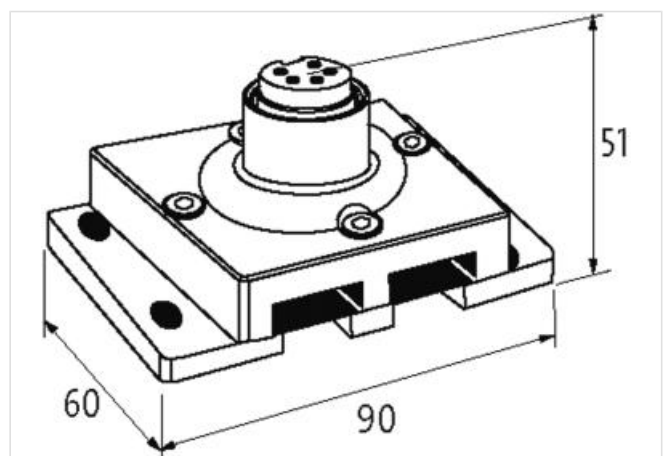

Product may differ from Image



Commercial data

ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219

ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
customs tariff number	85366990
customs tariff number	85369010
customs tariff number	85369010
GTIN	4048879052160
GTIN	4048879052160
GTIN	4048879052160
Packaging unit	1
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Operating voltage DC max.	36 V
Total current max.	8 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V

Mechanical data | Mounting data

Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm
Width	74 mm
Depth	52 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 60664-1
------------------	------------

Connection type 1

Family construction form	7/8"
Gender	female
Color contact carrier	black
No. of poles	5
PIN 1	AS-i +
PIN 2	AS-i -
PIN 3	n.c.
PIN 4	24 V DC
PIN 5	0 V