

## MA SI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to M12 male

Art.No.: 55038

Weight: 0.12

Country of origin: DE

Model designation: MASI67 Umsetzer 2x Profilk.-M12St



MA SI67 converter

2x profile cable to M12 (male)

Connection cables are in the online shop under "Connection Technology".

### [Link to Product](#)

#### Illustration

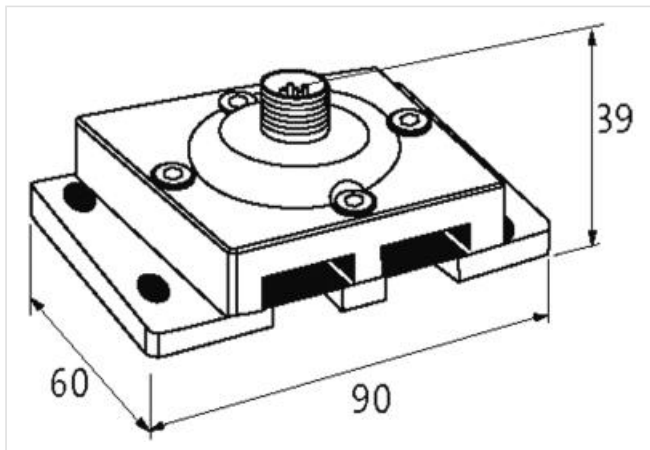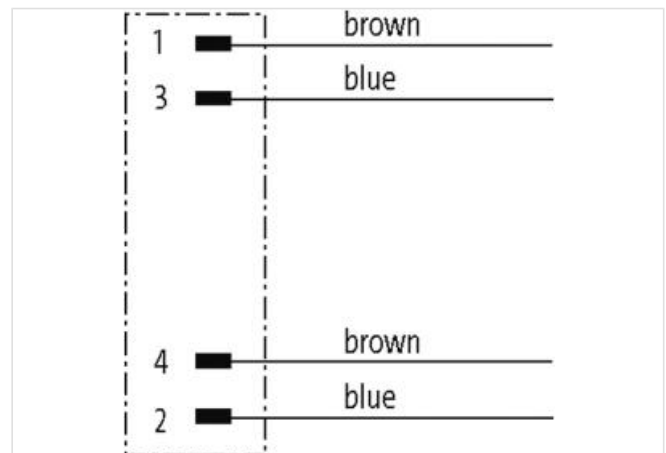

Product may differ from Image



#### Commercial data

ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219

ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
customs tariff number	85366990
customs tariff number	85369010
customs tariff number	85369010
GTIN	4048879052139
GTIN	4048879052139
GTIN	4048879052139
Packaging unit	1
Packaging unit	1
Packaging unit	1

#### Electrical data | Supply

Operating voltage DC max.	36 V
Total current max.	4 A

#### Device protection | Electrical

Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V

#### Mechanical data | Mounting data

Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm
Width	74 mm
Depth	39 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

#### Conformity

Product standard	EN 60664-1
------------------	------------

#### Connection type 1

Connection type 1	Bus In
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	5
PIN 1	AS-i +
PIN 2	0 V
PIN 3	AS-i -
PIN 4	24 V DC
PIN 5	n.c.