

MASI20 INSTALLATION TECHNOLOGY



Distributor 2x AS-I and 3x extern power

Art.No.: 55575
Weight: 0.142
Country of origin: CZ
Model designation: MASI Bus & 3x Power Verteiler IP20

2 AS-Interface + 3 power ports
potentially separated
5 plug terminals included

Link to Product

Illustration

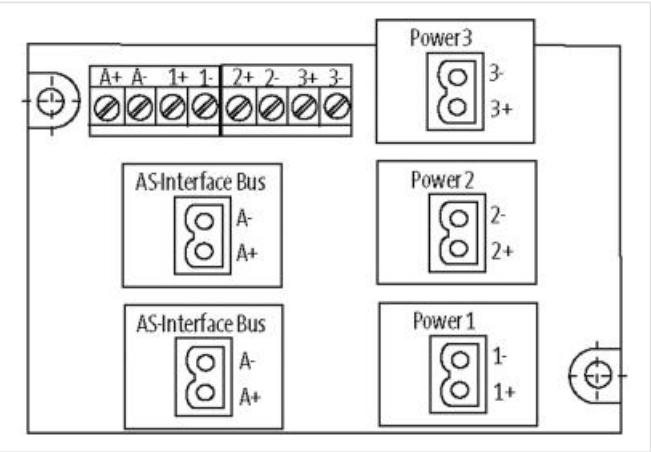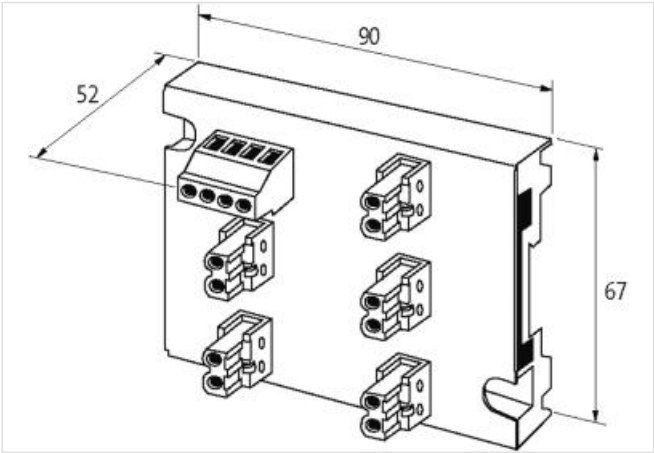

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27279219 |
| ECLASS-6.1 | 27279219 |
| ECLASS-7.0 | 27279219 |
| ECLASS-8.0 | 27279219 |

| | |
|-----------------------|---------------|
| ECLASS-9.0 | 27440108 |
| ECLASS-10.1 | 27440111 |
| ECLASS-11.1 | 27440111 |
| ECLASS-12.0 | 27440111 |
| ETIM-5.0 | EC001596 |
| customs tariff number | 85176200 |
| customs tariff number | 85176200 |
| GTIN | 4048879050593 |
| GTIN | 4048879050593 |
| Packaging unit | 1 |
| Packaging unit | 1 |

Electrical data | Supply

| | |
|---------------------------------|------|
| Operating voltage DC max. | 36 V |
| Current operating per port max. | 8 A |
| Total current max. | 24 A |

Device protection | Electrical

| | |
|-------------------------------------|-------|
| Degree of protection (EN IEC 60529) | IP20 |
| Insulation strength ASI/Power | 200 V |

Mechanical data | Mounting data

| | |
|----------------------------|---------------------------|
| Mounting method | geschnappt |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height | 52 mm |
| Width | 67 mm |
| Depth | 90 mm |

Environmental characteristics | Climatic

| | |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C |
| Storage temperature min. | -40 °C |
| Storage temperature max. | 80 °C |

Conformity

| | |
|------------------|------------|
| Product standard | EN 60664-1 |
|------------------|------------|

Connection type 5

| | |
|--------------------------|--------------------|
| Connection type 1 | Asi Bus |
| Connection type 2 | Power 1 |
| Connection type 3 | Power 2 |
| Connection type 4 | Power 3 |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 2 |
| PIN 1 | A + |
| PIN 2 | A - |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 2 |
| PIN 1 | 1 + |
| PIN 2 | 1 - |
| Connection | Screw terminals SK |
| Family construction form | terminal |

| | |
|--------------------------|--------------------|
| Gender | female |
| Color contact carrier | green |
| No. of poles | 2 |
| PIN 1 | 2 + |
| PIN 2 | 2 - |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 2 |
| PIN 1 | 3 + |
| PIN 2 | 3 - |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 8 |
| PIN 1 | A + |
| PIN 2 | A - |
| PIN 3 | 1 + |
| PIN 4 | 1 - |
| PIN 5 | 2 + |
| PIN 6 | 2 - |
| PIN 7 | 3 + |
| PIN 8 | 3 - |