

**MASI20 INSTALLATION TECHNOL.**

Plug terminal for AS-Interface profile cable

Art.No.: 55604

Weight: 0.008

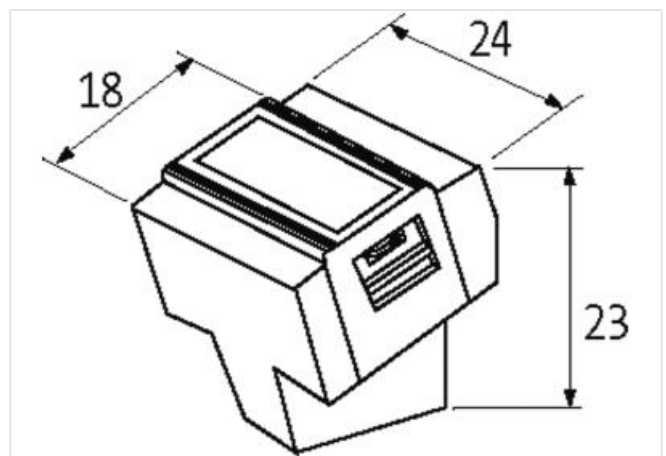
Country of origin: DE

Model designation: Steckklemme IP20 für ASI Profilkabel

Plug terminal  
for bus or power distributor

**[Link to Product](#)****Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27141106
ECLASS-6.1	27141104
ECLASS-7.0	27141104
ECLASS-8.0	27141104
ECLASS-9.0	27141104
ECLASS-10.1	27141104
ECLASS-11.1	27141104
ECLASS-12.0	27141104
ETIM-5.0	EC001583
customs tariff number	85369010
customs tariff number	85369010
GTIN	4048879050517
GTIN	4048879050517
Packaging unit	1
Packaging unit	1

**Electrical data | Supply**

Operating voltage DC max.	36 V
Total current max.	8 A

**Mechanical data | Mounting data**

Height	23 mm
Width	24 mm
Depth	18 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

**Connection type 1**

Connection	Screw terminals SK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	+
PIN 2	-