

Xenterra 8TX unmanaged Switch wallmounted 8 Port 100Mbit WM

Art.No.: 58903
Weight: 0.225
Country of origin: DE
Model designation: Xenterra 8TX WM


8 port unmanaged switch
Key-hole mounting/screwable
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

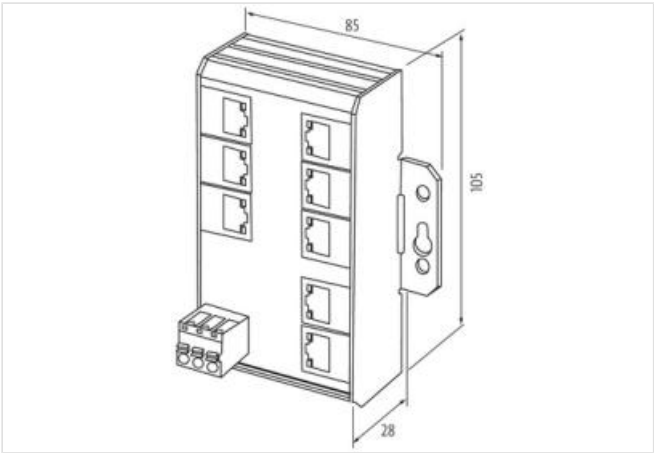

Commercial data

ECLASS-6.0	19170106
ECLASS-6.1	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170106
ECLASS-10.1	19170402
ECLASS-11.1	19170402
ECLASS-12.0	19170402
ETIM-5.0	EC000734
customs tariff number	85176200
customs tariff number	85176200
GTIN	4048879830409
GTIN	4048879830409
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Operating voltage AC min.	8 V
Operating voltage AC max.	28 V
Operating voltage DC min.	9 V
Operating voltage DC max.	36 V

Industrial communication

Data transmission rate max.	100 MBit/s
-----------------------------	------------

Industrial communication | Ethernet functionality

Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex
Switch type	unmanaged
VLAN unmanaged (IEEE 802.1Q)	yes

Diagnostics

Alarm contact	no
Diagnostic	No voltage
LED display	Ethernet connection/data traffic

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
-------------------------------------	------

Mechanical data | Material data

Material housing	Metal
Color housing	black

Mechanical data | Mounting data

Mounting method	screwed
Suitable for mounting type	Schlüssellochaufhängung
Height	105 mm
Width	85 mm
Depth	28 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	70 °C
Storage temperature min.	-40 °C
Storage temperature max.	85 °C

Connection type 1

Connection type 1	8
Family construction form	RJ45
Gender	female
Color contact carrier	black
No. of poles	8
PIN 1	TD +
PIN 2	TD -
PIN 3	RD +
PIN 4	n.c.
PIN 5	n.c.
PIN 6	RD -
PIN 7	n.c.
PIN 8	n.c.