

S-Lamp 30 S L M12(4)

Lamp

Art.No.: 69115  
Weight: 0.023  
Country of origin: HU  
Model designation: S-Lamp 30 S L M12(4)

S-Lamp 30 S L M12(4)

Lamp


Frontring stainless steel  
Mounting hole 30,3 mm  
Connection M12 (4-pin)

Link to Product

Illustration



Product may differ from Image

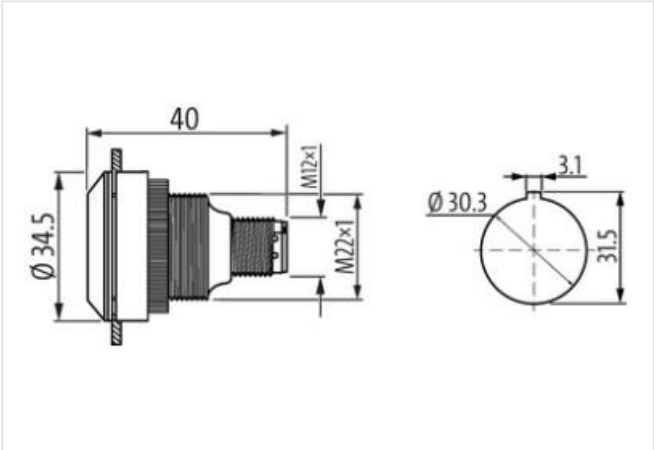

Commercial data	
ECLASS-6.1	27371223
ECLASS-7.0	27371223
ECLASS-8.0	27371223
ECLASS-9.0	27371223
ECLASS-10.1	27371223
ECLASS-11.1	27371223
ECLASS-12.0	27371223
ETIM-5.0	EC000272
ETIM-6.0	EC000272
ETIM-7.0	EC000272
ETIM-8.0	EC000272
customs tariff number	94054231
customs tariff number	94054231
GTIN	4065909019641
GTIN	4065909019641
Packaging unit	1
Packaging unit	1

<b>Electrical data   Supply</b>	
Operating voltage DC	24 V
Operating voltage DC min.	20 V
Operating voltage DC max.	28 V
Rated operating current	0,01 A
Operating current max.	12 mA
<b>Electrical data   Input</b>	
Short-circuit current	1000 A
<b>Installation   Connection</b>	
Family construction form	M12
<b>Installation   Pin assignment</b>	
Coding	A
No. of poles	4
<b>Device protection   Electrical</b>	
Installation height max. ASL	2000 m
Degree of protection front (EN IEC 60529)	IP66, IP67, IP69
Degree of protection back (EN IEC 60529)	IP66, IP67
Pollution Degree	2
Short circuit protective device (SCPD)	fuse 250 V / 0.1 A / 1.5 kA gG quick
Rated insulation voltage	250 V
Overvoltage category (EN 60950-1)	II
<b>Device protection   Mechanical</b>	
UL enclosure type rating front side	type 4X
<b>Device protection   Media</b>	
Salt-spray resistance (IEC 60068-2-11)	yes
<b>Mechanical data</b>	
Can be illuminated	yes
Color	black
Color collar	black
Color front ring	Stainless steel
Color illuminant	white
Shape collar	round
Type of illuminant	LED
<b>Mechanical data   Material data</b>	
Material housing	Plastic
<b>Mechanical data   Mounting data</b>	
Mounting method	Threaded ring
Installation height	3,9 mm
Mounting depth	36,4 mm
Mounting hole	30,3 mm
Height	34,5 mm
Width	40 mm
Grid min.	35 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-25 °C
Operating temperature max.	70 °C
Derating from	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	90 °C
Relative humidity max. (operation)	93 %

**Connection type 2**

Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	4
PIN 2	LED (A)
PIN 3	LED (K)
Family construction form	M12
Gender	male
Coding	A
No. of poles	4
PIN 2	LED (A)
PIN 3	LED (K)