

MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER



P: 1000VA IN: 240-415VAC OUT: 110-110-20VAC

Art.No.: 86055
Weight: 14.55
Country of origin: CZ
Model designation: MET 1000-240-415/110-240

Single-phase - Control and Isolation Transformers
1000 VA
Isolation class T 60/B

Link to Product

Illustration

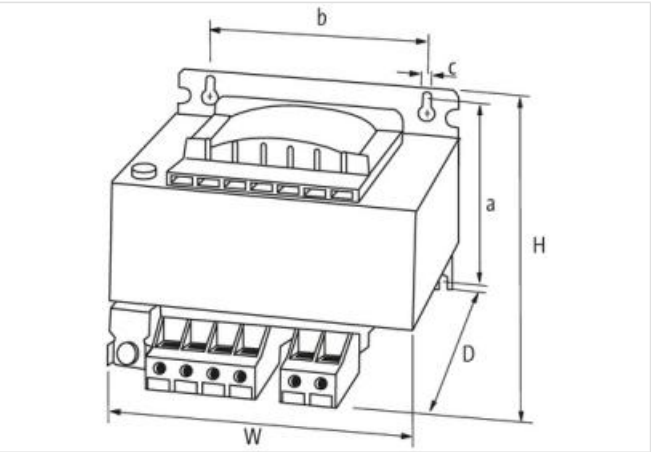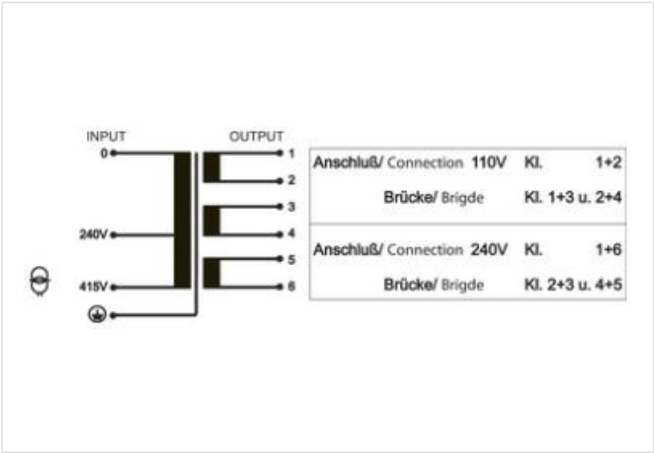

Product may differ from Image



Commercial data

ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302

ECLASS-9.0	27031302
ECLASS-10.1	27031302
ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
customs tariff number	85043180
customs tariff number	85043180
GTIN	4048879078863
GTIN	4048879078863
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage 1 AC	240 V
Input voltage 2 AC	415 V
Input current at input voltage 1 AC	4,64 A
Input current at input voltage 2 AC	2,68 A
Inrush current at input voltage 1	110 A
Inrush current at input voltage 2	62,5 A
Short-circuit current at input voltage 1	138 A
Short-circuit current at input voltage 2	79,4 A

Electrical data | Output

Output voltage AC 1	110 V
Output voltage AC 2	240 V
Output voltage adjustable	yes
Power rating AC max.	1000 VA

Device protection | Electrical

Insulation test voltage input - output	4 kV
--	------

Mechanical data | Mounting data

Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	111,5 mm
Mounting dimension b	135 mm
Mounting dimension c	7 mm
Height	138 mm
Width	174 mm
Depth	160 mm
Diameter bore	7 mm
Length bore	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0
------------------	---