


Modlink MSDD set contains:

Frame 4000-68512-0000001
Art.No.: 4000-68512-4030001
Weight: 0.139
Country of origin: US
Model designation: MSDD_1transparent_NEMA5-15RIöt,RJ45Cat5e

Link to Product

Illustration

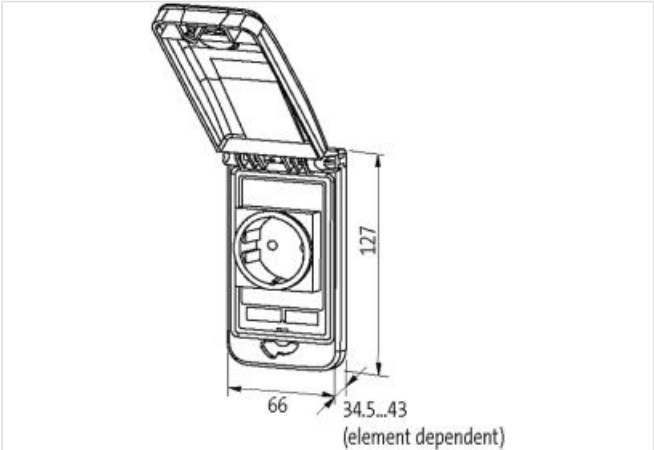

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27189234 |
| ECLASS-6.1 | 27189217 |
| ECLASS-7.0 | 27189217 |
| ECLASS-8.0 | 27189217 |
| ECLASS-9.0 | 27182806 |
| ECLASS-10.1 | 27182806 |

| | |
|-----------------------|---------------|
| ECLASS-11.1 | 27182806 |
| ECLASS-12.0 | 27182806 |
| ETIM-5.0 | EC002625 |
| ETIM-6.0 | EC002625 |
| ETIM-7.0 | EC002625 |
| ETIM-8.0 | EC002625 |
| customs tariff number | 85366990 |
| customs tariff number | 85366990 |
| GTIN | 4048879691703 |
| GTIN | 4048879691703 |
| Packaging unit | 1 |
| Packaging unit | 1 |

Frame

| | |
|---|-------------|
| Degree of protection (EN IEC 60529) | IP65 |
| Operating temperature min. | -30 °C |
| Operating temperature max. | 70 °C |
| Storage temperature min. | -30 °C |
| Storage temperature max. | 80 °C |
| Suitable for installation wall thickness min. | 1 mm |
| Suitable for installation wall thickness max. | 5 mm |
| Material housing | PA |
| Color housing | black |
| Material lid | PC |
| Color cover | transparent |

USA

| | |
|----------------------------|------------------------|
| Connection geometry | 4.8 x 0.5 mm |
| Operating voltage AC | 125 V |
| Operating current | 15 A |
| Connection | Plug-solder connection |
| No. of poles | 2 + PE |
| Protection contact present | yes |

USB

| | |
|---------------------------------------|-------------------|
| Operating voltage AC | 48 V |
| Operating voltage DC | 48 V |
| Operating voltage AC max. (UL-listed) | 30 V |
| Operating voltage DC max. (UL-listed) | 42,4 V |
| Operating current | 1,5 A |
| USB specification | 3.0 |
| Data transmission rate max. | 5000 MBit/s |
| Looking techniques | Snap-in connector |

RJ45

| | |
|---------------------------------------|-------------------|
| Operating voltage AC max. (UL-listed) | 30 V |
| Operating voltage DC max. (UL-listed) | 42,4 V |
| Current operating max. (UL) | 175 mA |
| Family construction form | RJ45 |
| Family type Back side | RJ45 |
| Cable category min. | Cat5e |
| Looking techniques | Snap-in connector |