

**EOL - Modlink MSDD set contains: Frame 4000-68513-0000001**


discontinued - End of Life Date: 2024-12-31


Art.No.: 4000-68513-4040001

Weight: 0.123

Country of origin: DE

Model designation: X MSDD\_1metallic\_NEMA5-15R Iöt,RJ45 Cat5

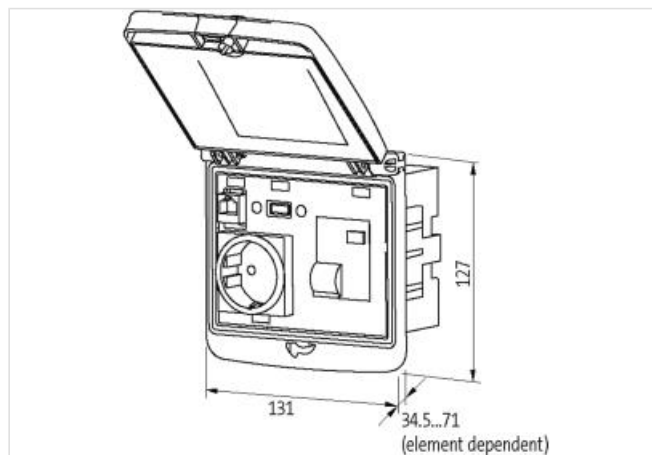[Link to Product](#)**Illustration**

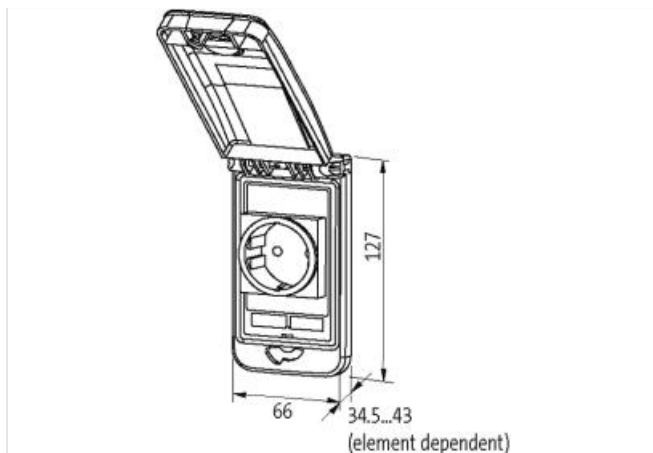

Product may differ from Image

**Commercial data**

ECLASS-6.0	27189234
ECLASS-7.0	27189234
ECLASS-8.0	27189234
ECLASS-9.0	27189234
ETIM-5.0	EC002625
customs tariff number	85366990
customs tariff number	85366990
customs tariff number	85366990
customs tariff number	85366990
GTIN	4048879695220
GTIN	4048879695220
GTIN	4048879695220
GTIN	4048879695220
Packaging unit	1
Packaging unit	1
Packaging unit	1
Packaging unit	1

**Frame**

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Material housing	PA
Color housing	black
Material lid	ABS
Color cover	metallic

**USA**

Connection geometry	4.8 x 0.5 mm
Operating voltage AC	125 V

Operating current	15 A
Connection	Plug-solder connection
No. of poles	2 + PE
Protection contact present	yes

**RJ45**

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector