


Modlink MSDD set contains:

Frame 4000-68522-0000001
Art.No.: 4000-68522-4110001
Weight: 0.401
Country of origin: US
Model designation: MSDD_2transparent_GFCI 15A+RJ45+3A fuse_
with touch protection

Link to Product

Illustration

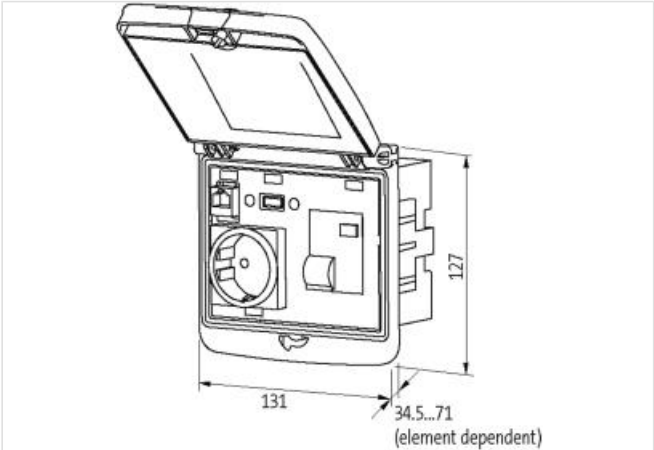

Product may differ from Image



Commercial data	
ECLASS-6.0	27189234
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806

ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
customs tariff number	85366990
customs tariff number	85366990
GTIN	4048879691864
GTIN	4048879691864
Packaging unit	1
Packaging unit	1

Frame

Degree of protection (EN IEC 60529)	IP65
Operating temperature min.	-30 °C
Operating temperature max.	70 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C
Suitable for installation wall thickness min.	1 mm
Suitable for installation wall thickness max.	5 mm
Material housing	PA
Color housing	black
Material lid	PC
Color cover	transparent

Fuse

Operating voltage AC	250 V
Operating voltage DC	32 V
Nominal current	3 A

USA

Connection cross section max.	6 mm ²
AWG number max.	10
Operating voltage AC	125 V
Operating current	15 A
Connection	Screw terminals SK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes

RJ45

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector