

MSDD pass-through RJ45 CAT6A femal/femal, design silver

Art.No.: 4000-73000-0020000

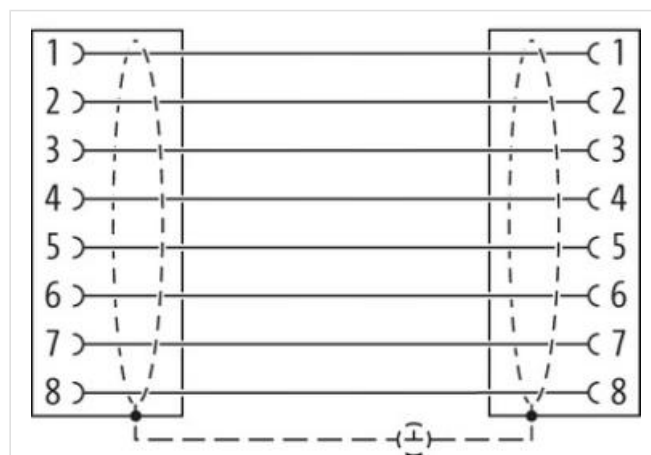
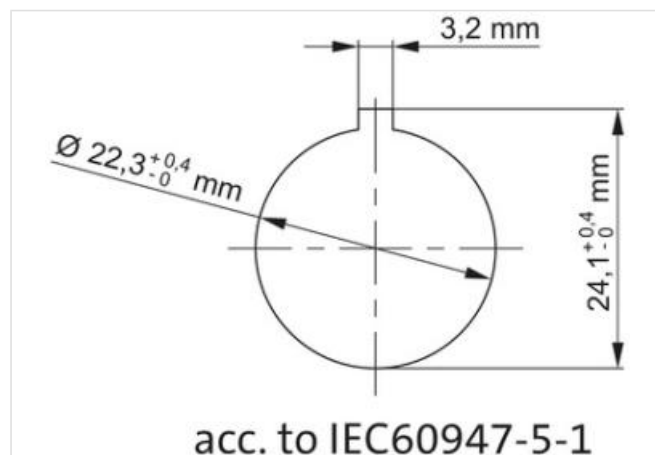
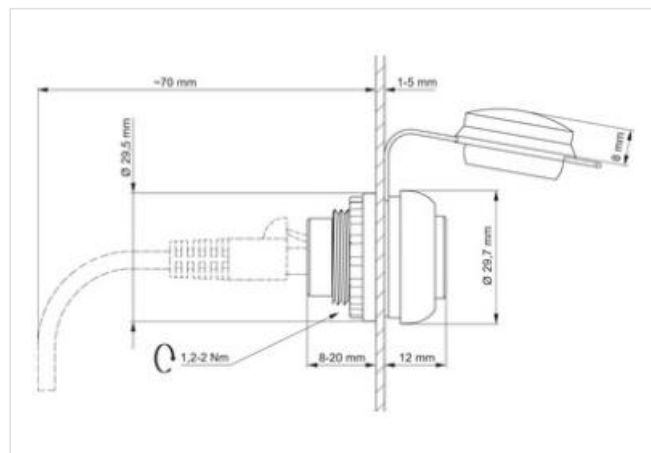
Weight: 0.024

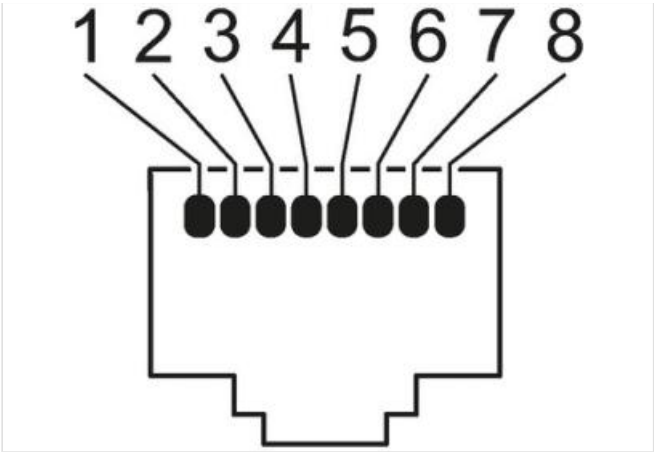
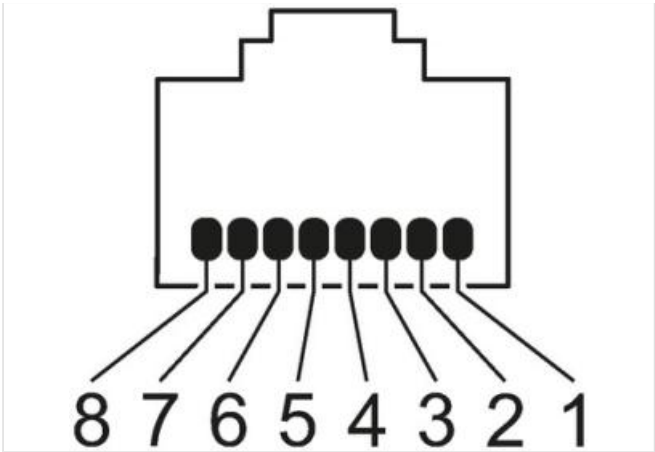
Country of origin: CZ

Model designation: MSDD PT22-S RJ45 CAT6A F/F

Pass-through

1 × RJ45, 8-pole metal, CAT6A (female/female)

[Link to Product](#)**Illustration**



Product may differ from Image



Commercial data	
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
customs tariff number	85366990
customs tariff number	85366990
GTIN	4065909037256
GTIN	4065909037256
Packaging unit	1
Packaging unit	1
Electrical data Supply	
Operating voltage AC	24 V
Operating voltage DC	24 V
Operating current max.	1,5 A
Installation Connection	
Family construction form	RJ45
Gender	female
Gender Rear	female
Cable category min.	Cat6a
Device protection	
Shielded	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state
Device protection Mechanical	

Mechanical endurance 750 Cycles

Mechanical data | Mounting data

Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	20 mm

Approvals

UL 50E yes