

**MSDD pass-through USB 3.0 form A, 0.6 m cable, design black**

Neutral lid without logo

Art.No.: 4000-73000-0150001

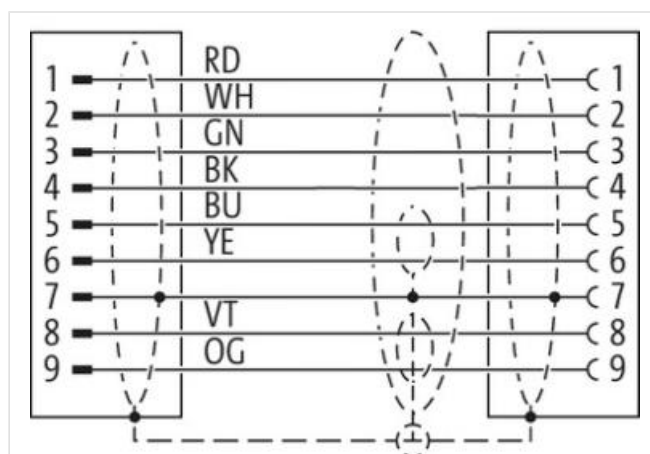
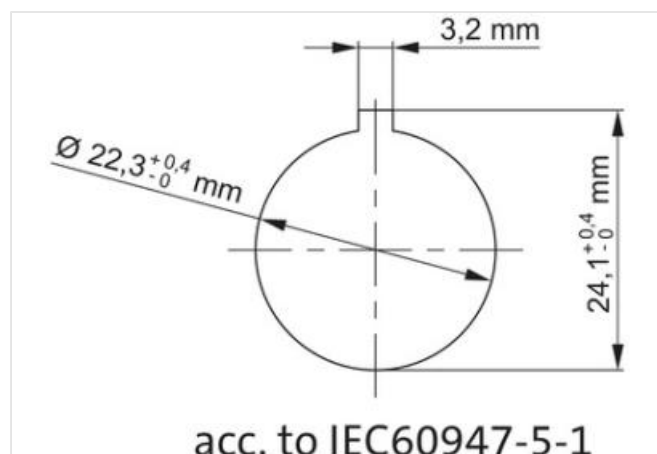
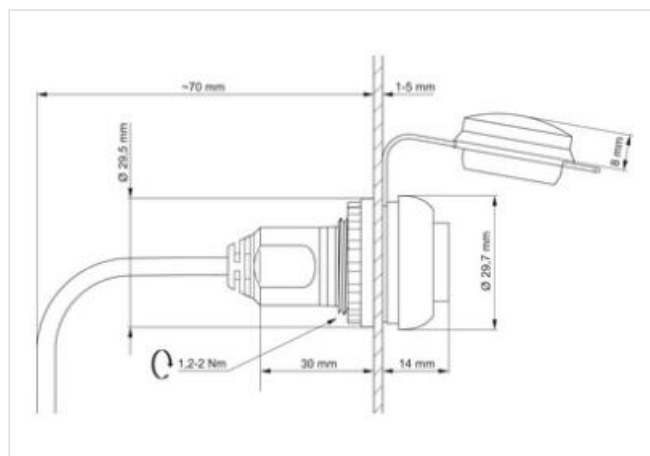
Weight: 0.059

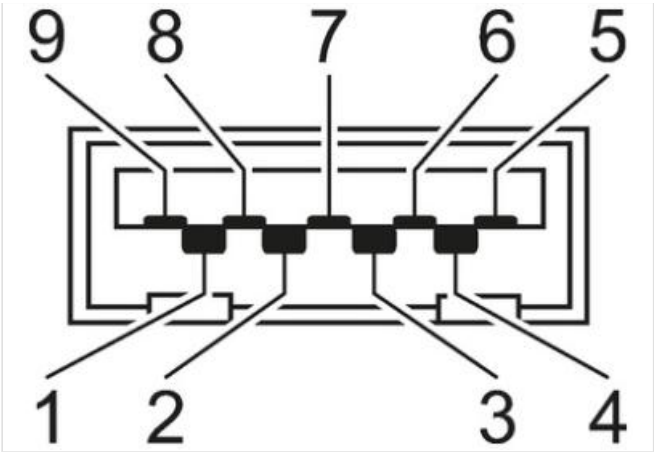
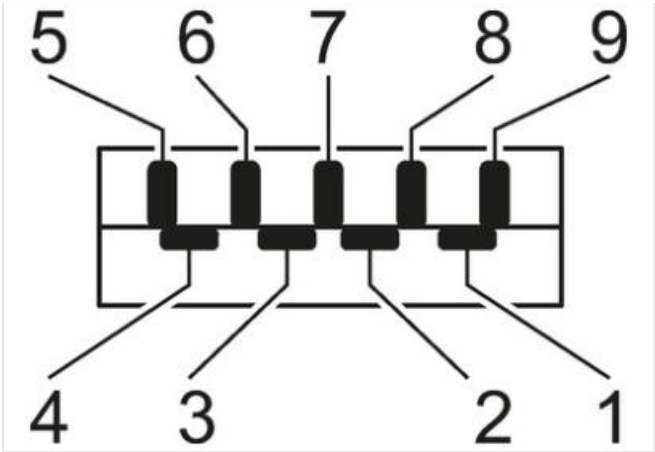
Country of origin: CZ

Model designation: MSDD PT22-B USB3.0 A/A F/M\_0.6

Pass-through

1 × USB 3.0 (female/male/0.6 m cable) form A

[Link to Product](#)
**Illustration**




Product may differ from Image



Commercial data	
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
customs tariff number	85444290
customs tariff number	85444290
GTIN	4065909037263
GTIN	4065909037263
Packaging unit	1
Packaging unit	1
Electrical data   Supply	
Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA
Industrial communication	
USB specification	3.0
Device protection	
Shielded	yes
Device protection   Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state
Device protection   Mechanical	

Mechanical endurance 1500 Cycles

**Mechanical data | Mounting data**

Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	30 mm

**Approvals**

UL 50E yes