

MSDD pass-through USB 3.0 form A, 1.0 m cable, design silver

Art.No.: 4000-73000-0160000

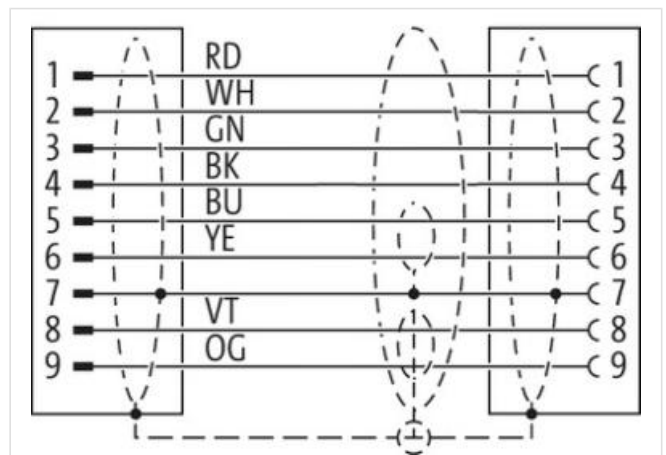
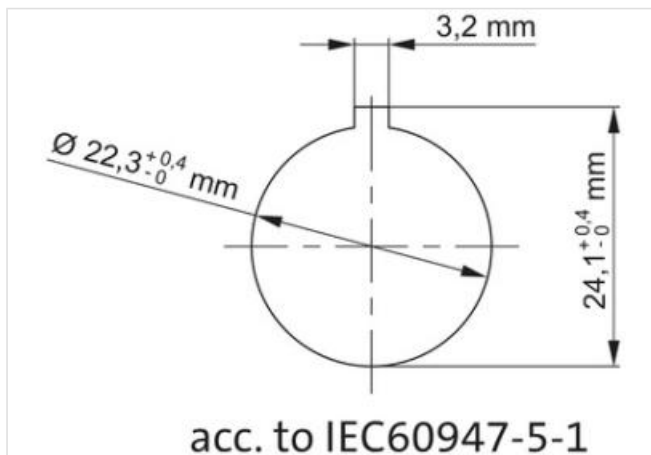
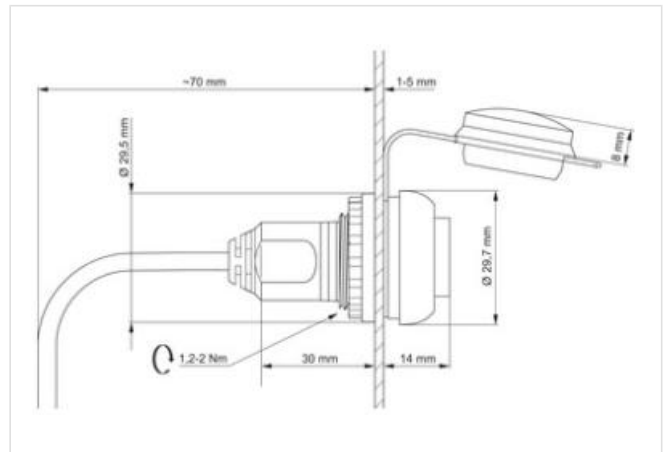
Weight: 0.074

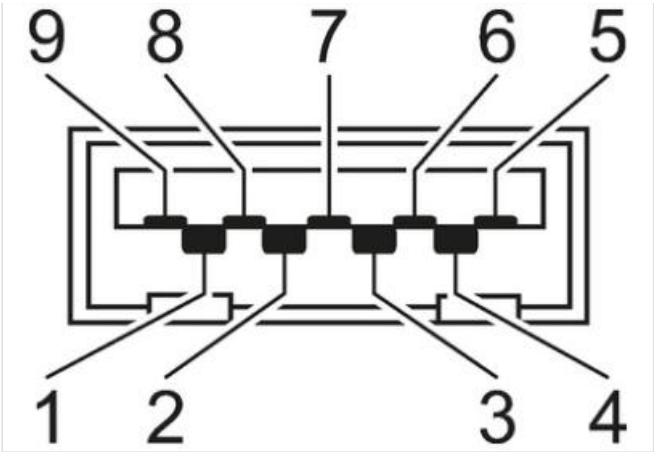
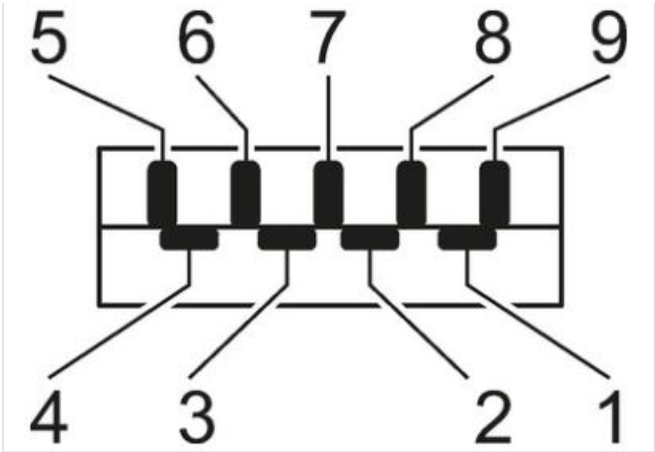
Country of origin: CZ

Model designation: MSDD PT22-S USB3.0 A/A F/M_1.0

Pass-through

1 × USB 3.0 (female/male/1.0 m cable) form A

[Link to Product](#)**Illustration**



Product may differ from Image



| Commercial data | |
|--|---------------------------|
| ECLASS-6.0 | 27143423 |
| ECLASS-6.1 | 27143419 |
| ECLASS-7.0 | 27440515 |
| ECLASS-8.0 | 27440515 |
| ECLASS-9.0 | 27440515 |
| ECLASS-10.1 | 27440515 |
| ECLASS-11.1 | 27440515 |
| ECLASS-12.0 | 27440515 |
| ETIM-5.0 | EC002625 |
| ETIM-6.0 | EC002625 |
| ETIM-7.0 | EC002625 |
| ETIM-8.0 | EC002625 |
| customs tariff number | 85444290 |
| customs tariff number | 85444290 |
| GTIN | 4048879433402 |
| GTIN | 4048879433402 |
| Packaging unit | 1 |
| Packaging unit | 1 |
| Electrical data Supply | |
| Operating voltage AC | 5 V |
| Operating voltage DC | 5 V |
| Operating current max. | 900 mA |
| Industrial communication | |
| USB specification | 3.0 |
| Device protection | |
| Shielded | yes |
| Device protection Electrical | |
| Degree of protection (EN IEC 60529) | IP20, IP65 |
| Protection NEMA | 2, 3R, 4, 12, 13, 4x |
| Additional condition protection degree | inserted, in closed state |
| Device protection Mechanical | |

Mechanical endurance 1500 Cycles

Mechanical data | Mounting data

| | |
|-----------------|---------|
| Diameter cutout | 22,5 mm |
| Diameter | 29,5 mm |
| Mounting depth | 70 mm |
| Depth | 30 mm |

Approvals

UL 50E yes