

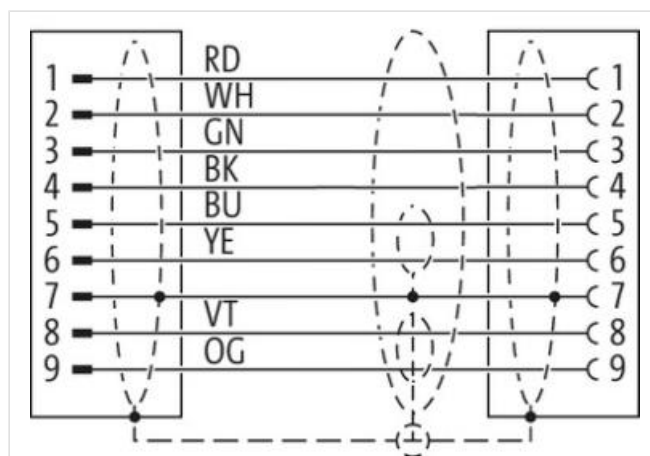
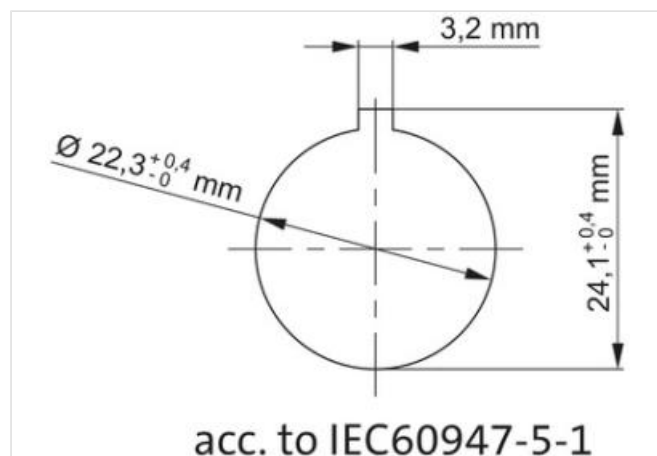
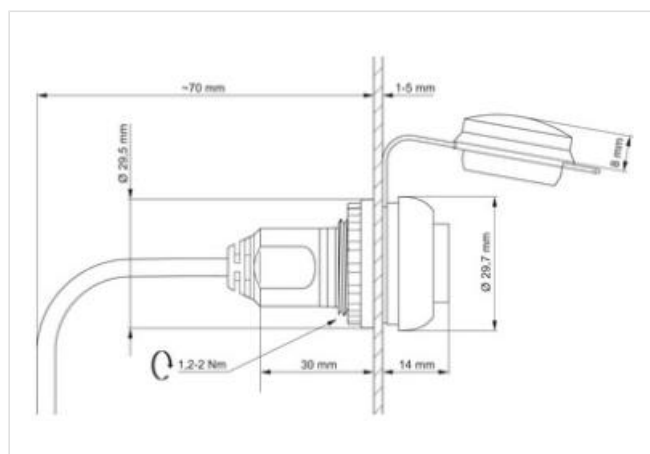
MSDD pass-through USB 3.0 form A, 5.0 m cable, design silver

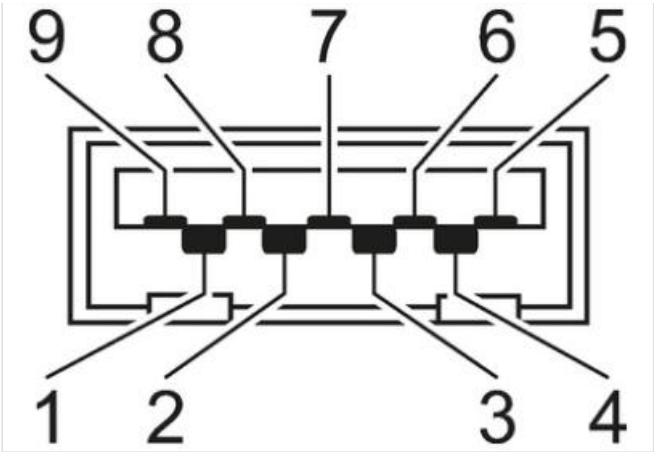
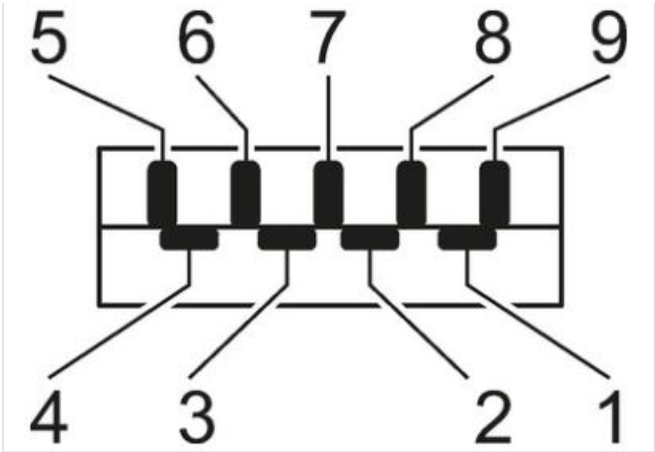
Art.No.: 4000-73000-0240000

Weight: 0.232

Country of origin: CZ

Model designation: MSDD PT22-S USB3.0 A/A F/M_5.0

[Link to Product](#)
Illustration




Product may differ from Image



Commercial data	
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
customs tariff number	85444290
GTIN	4048879857017
Packaging unit	1
Electrical data Supply	
Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA
Industrial communication	
USB specification	3.0
Device protection	
Shielded	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state
Device protection Mechanical	
Mechanical endurance	1500 Cycles
Mechanical data Mounting data	
Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	30 mm
Approvals	

UL 50E

yes