

**Bus terminating plug M12 female A-cod.**

Devicenet

Art.No.: 7000-13471-0000000

Weight: 0.012

Country of origin: DE

Model designation: MSB05L0-5 4-5R

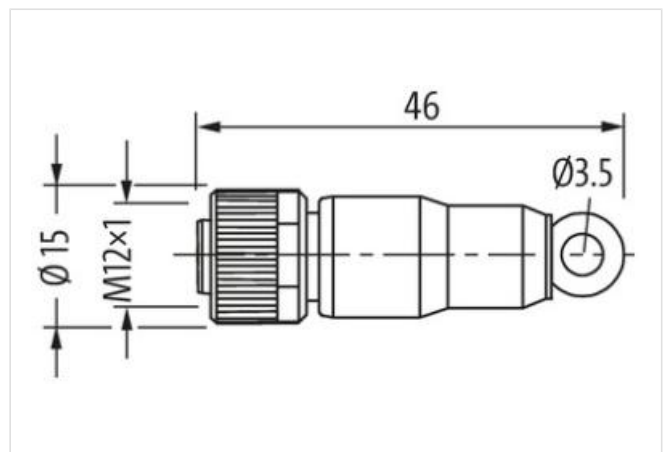
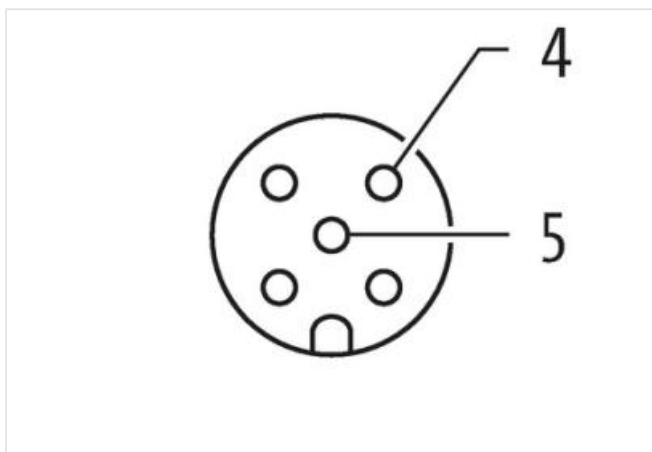
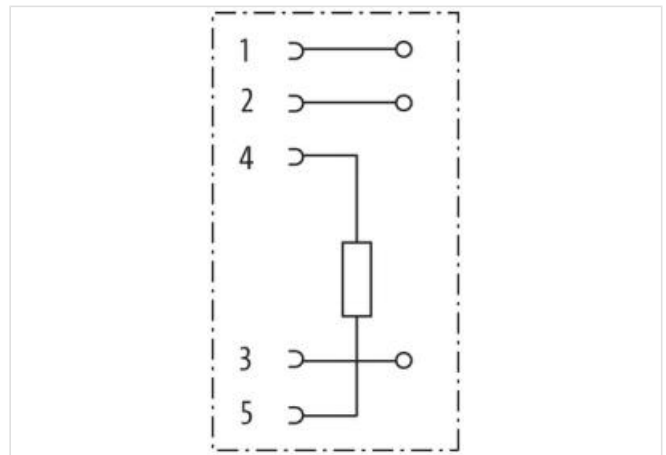
DeviceNet, CANopen

Terminating resistor

Female

M12 – M12, 5-pole (circuit diagram)

A-coded

**[Link to Product](#)****Illustration**

Product may differ from Image

**Side 1**

Family construction form M12

Degree of protection (EN IEC 60529) IP67

Commercial data	
ECLASS-6.0	19070403
ECLASS-6.1	27260702
ECLASS-7.0	27440390
ECLASS-8.0	27440190
ECLASS-9.0	27440190
ECLASS-10.1	27440190
ECLASS-11.1	27440190
ECLASS-12.0	27440190
ETIM-5.0	EC001855
customs tariff number	85332100
customs tariff number	85332100
GTIN	4048879198752
GTIN	4048879198752
Packaging unit	1
Packaging unit	1
Electrical data   Supply	
Operating voltage DC max.	30 V
Operating voltage DC max. (UL-listed)	30 V
Current operating per contact max.	4 A
Installation   Connection	
Tightening torque	0,6 Nm
Device protection   Electrical	
Additional condition protection degree	inserted, screwed
Mechanical data   Material data	
Coating locking	Nickel
Locking material	Zinc die-casting
Mechanical data   Mounting data	
Mounting method	inserted, screwed, Shaking protection
Environmental characteristics   Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C