

Bus terminating plug M12 male A-cod.

CUBE67

Art.No.: 7000-15041-0000000

Weight: 0.012

Country of origin: DE

Model designation: MSA05L0-6p* 4-5R

Cube67

Terminating resistor

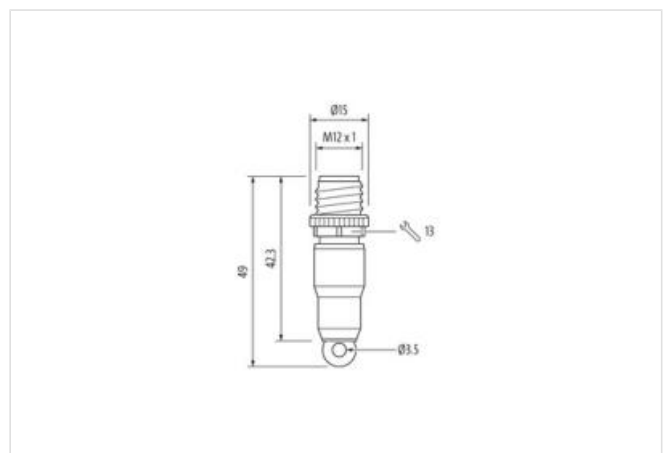
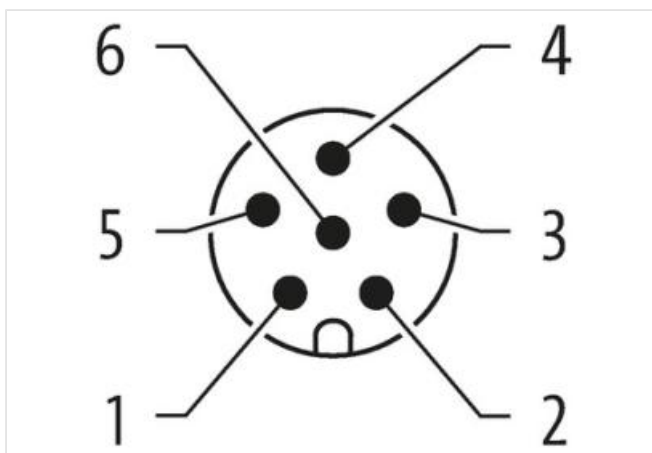
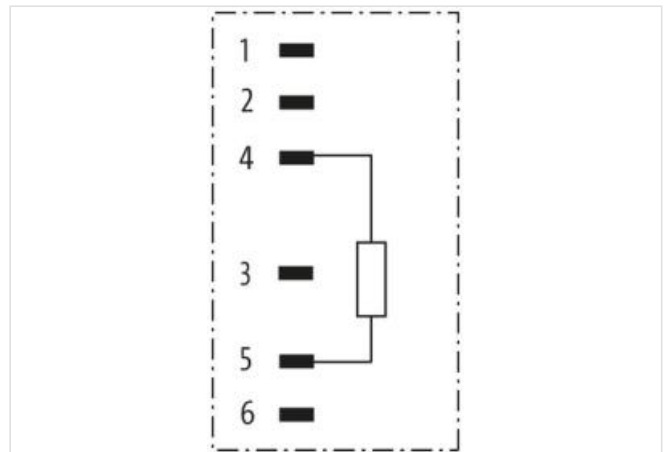
Male

M12, 6-pole

A-coded

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Side 1**

Tightening torque	0,6 Nm
Family construction form	M12
Degree of protection (EN IEC 60529)	IP67
Commercial data	
ECLASS-6.0	19070403
ECLASS-7.0	19070403
ECLASS-8.0	19070403
ECLASS-9.0	19070403
ECLASS-10.1	19070403
ECLASS-11.1	19070403
ECLASS-12.0	19070403
ETIM-5.0	EC001855
customs tariff number	85332100
customs tariff number	85332100
GTIN	4048879196963
GTIN	4048879196963
Packaging unit	1
Packaging unit	1
Electrical data Supply	
Operating voltage DC max.	30 V
Operating voltage DC max. (UL-listed)	30 V
Current operating per contact max.	4 A
Device protection Electrical	
Additional condition protection degree	inserted, screwed
Mechanical data Mounting data	
Mounting method	inserted, screwed, Shaking protection
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C