

Blind module

Art.No.: 70MH-MAA10-0000000

Weight: 0.005

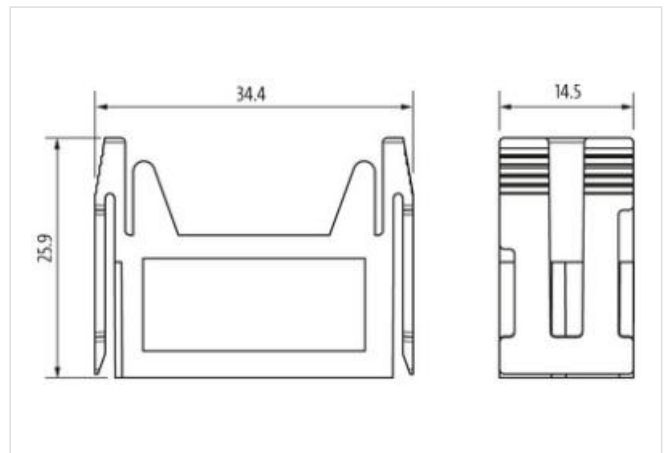
Country of origin: CZ

Model designation: MSMH-MBM-1M

Blind module

Male/female

Technical data will be only guaranteed with Murrelektronik components.

Link to Product**Illustration**

Product may differ from Image

Commercial data

ECLASS-6.0	27143424
ECLASS-6.1	27261290
ECLASS-7.0	27440290
ECLASS-8.0	27440290
ECLASS-9.0	27440292
ECLASS-10.1	27440292
ECLASS-11.1	27440292
ECLASS-12.0	27440292
ETIM-5.0	EC000438
customs tariff number	85389099
GTIN	4048879641517
Packaging unit	5

Installation | Connection

Mating cycles min.	500
--------------------	-----

Device protection | Electrical

Pollution Degree	3
------------------	---

Mechanical data

Holding force modules min.	150 N
----------------------------	-------

Mechanical data | Material data

Material housing	PA
Combustibility class (UL94)	V-0

Mechanical data | Mounting data

Number of module slots	1
Height	25,9 mm
Width	15,4 mm
Depth	34,4 mm

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
Operating temperature max.	125 °C
Climatic category (EN IEC 60068-1)	40/125/10