

Shielded male module, 2-pole

50 V, 10 A

Art.No.: 70MH-MAD2C-0020101

Weight: 0.013

Country of origin: CZ

Model designation: MSMH-MSTGM-2M-C-2 pol. 50 V 10 A

Male

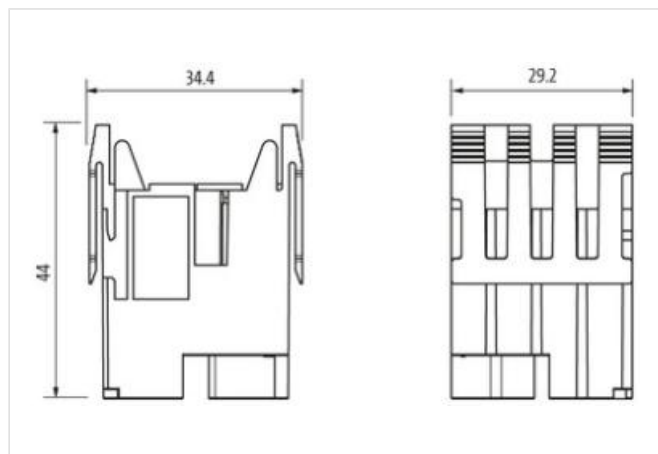
2-pole

Koax

Technical data will be only guaranteed with Murrelektronik components.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27143424
ECLASS-6.1	27261204
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440217
ECLASS-10.1	27440217
ECLASS-11.1	27440217
ECLASS-12.0	27440217
ETIM-5.0	EC000438
customs tariff number	85389099
customs tariff number	85389099
GTIN	4048879641845
GTIN	4048879641845
Packaging unit	5
Packaging unit	5

Installation | Connection

Gender	male
Mating cycles min.	500

Installation | Pin assignment

No. of poles	2
--------------	---

Device protection | Electrical

Pollution Degree	3
------------------	---

Overvoltage category (EN 60664-1)	I
-----------------------------------	---

Mechanical data | Material data

Material housing	PA
------------------	----

Combustibility class (UL94)	V-0
-----------------------------	-----

Mechanical data | Mounting data

Number of module slots	2
------------------------	---

Height	44 mm
--------	-------

Width	29,2 mm
-------	---------

Depth	34,4 mm
-------	---------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	125 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/125/10
------------------------------------	-----------