

Pneumatic module - female & male, 3-pole

Art.No.: 70MH-MAP10-0030000
Weight: 0.006
Country of origin: PL
Model designation: MSMH-MBUSTM-1M-PNEUMATIKMODUL-3pol.


Pneumatic
Male/female
3-pole
Internal hose Ø 1.6, 3, 4 mm
Technical data will be only guaranteed with Murrelektronik components.
The clip 70MH-ZZ100-0000000 is needed (2×)

Link to Product

Illustration



Product may differ from Image

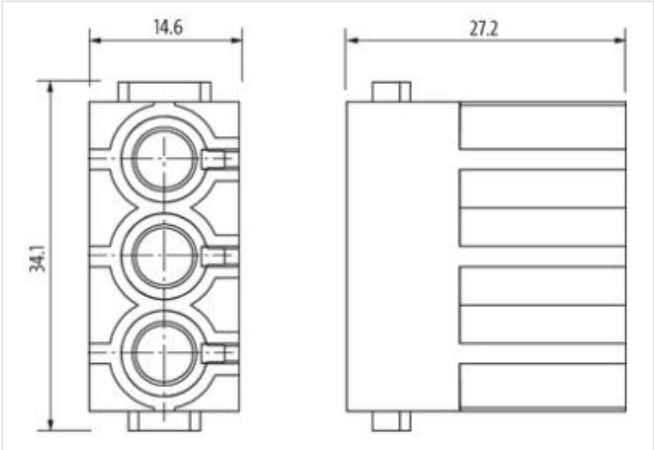

Commercial data

ECLASS-6.0	27440209
ECLASS-6.1	27261204
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440204
ECLASS-10.1	27440204
ECLASS-11.1	27440204
ECLASS-12.0	27440204
ETIM-5.0	EC000438
customs tariff number	85389099
customs tariff number	85389099
GTIN	4048879664141
GTIN	4048879664141
Packaging unit	5
Packaging unit	5

Installation | Connection

Gender	male/female
--------	-------------

Mating cycles min.	500
--------------------	-----

Installation | Pin assignment

No. of poles	3
--------------	---

Device protection | Electrical

Pollution Degree	3
------------------	---

Mechanical data | Material data

Material housing	PC
------------------	----

Combustibility class (UL94)	V-0
-----------------------------	-----

Mechanical data | Mounting data

Number of module slots	1
------------------------	---

Height	27,2 mm
--------	---------

Width	34,1 mm
-------	---------

Depth	14,6 mm
-------	---------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	80 °C
----------------------------	-------