

**EXACT12, 4XM12, 4 POLE BASIC HOUSING, W.O. LED'S**

Without homerun-cable

Art.No.: 8000-84402-0000000

Weight: 0.076 kg

Country of origin: DE

Model designation: MVP12N-MK4V-XA

4-way, 4-pole

without LED, up to 125 V AC/DC




Screw plug-in terminals



Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

**Illustration**

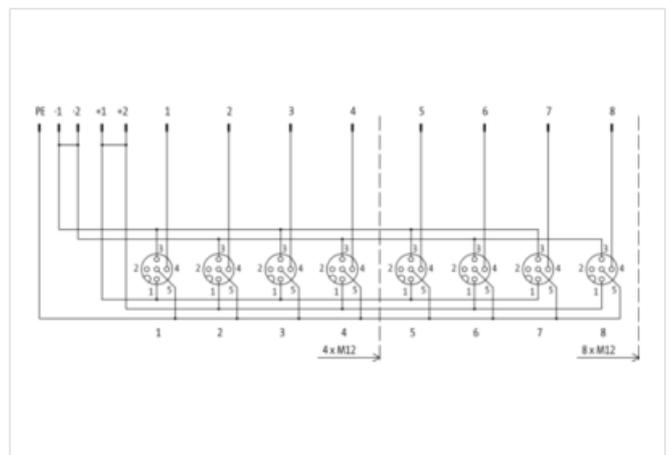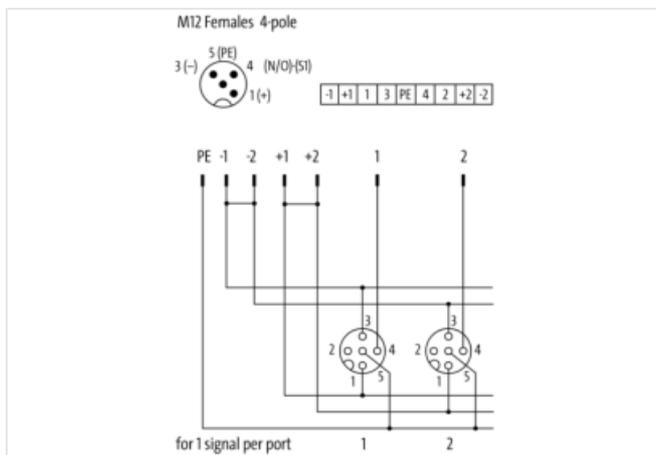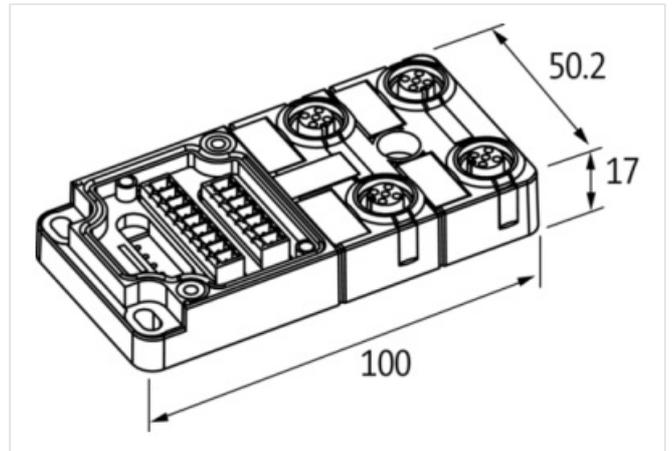

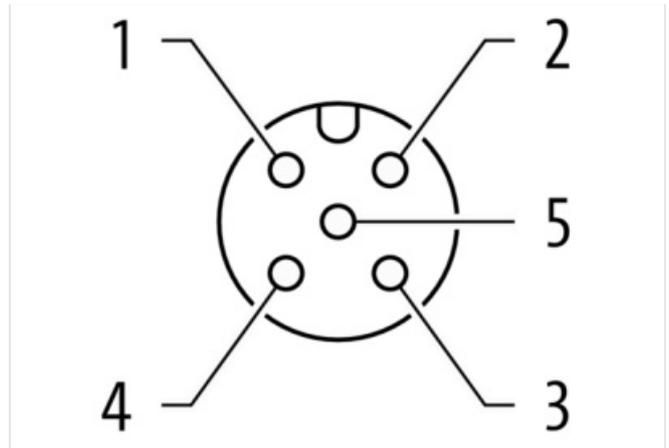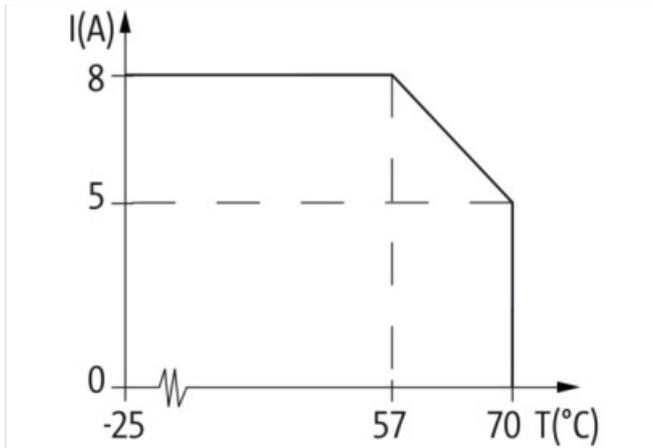

Product may differ from Image

**Commercial data**

URL Webshop	<a href="https://shop.murrelektronik.com/8000-84402-0000000">https://shop.murrelektronik.com/8000-84402-0000000</a>
GTIN	4048879056069
Customs tariff number	85366990
ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
customs tariff number	85366990
EAN	4048879056069
Packaging unit	1

**Electrical data | Supply**

Operating voltage AC	125 V
Operating voltage DC	125 V
Current operating per contact max.	4 A
Total current max.	8 A

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP67, IP65
-------------------------------------	------------

**Device protection | Media**

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-05-06

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

