

EXACT12, 4XM12, 4 POLE BASIC HOUSING, W.O. LED'S

Without homerun-cable

Art.No.: 8000-84402-0000000

Weight: 0.076

Country of origin: DE

Model designation: MVP12N-MK4V-XA

4-way, 4-pole

without LED, up to 125 V AC/DC




Screw plug-in terminals



Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

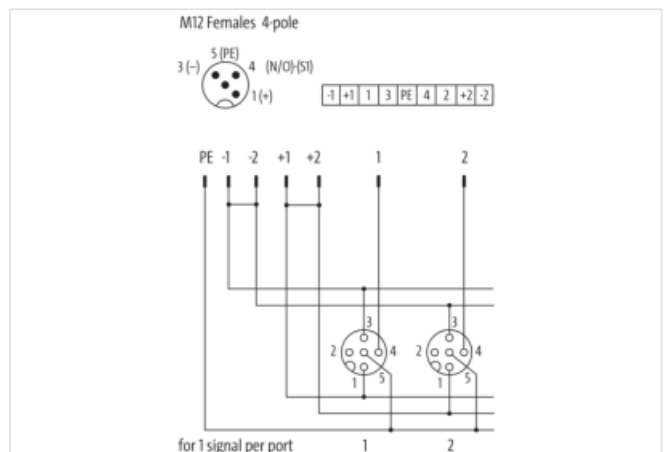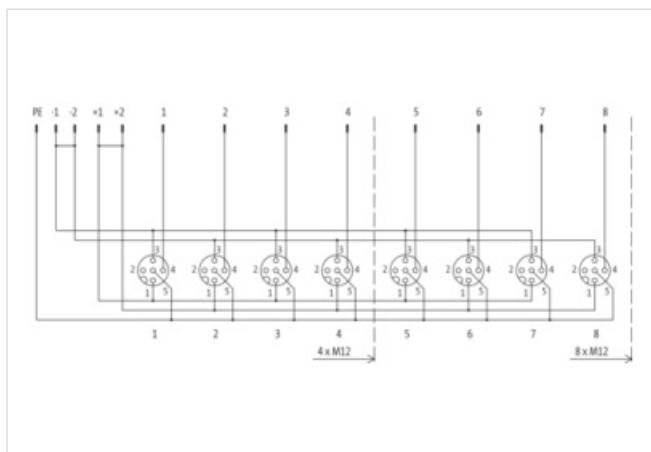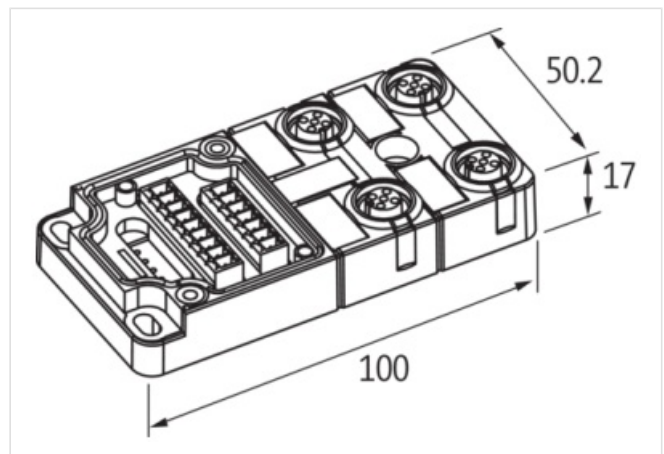

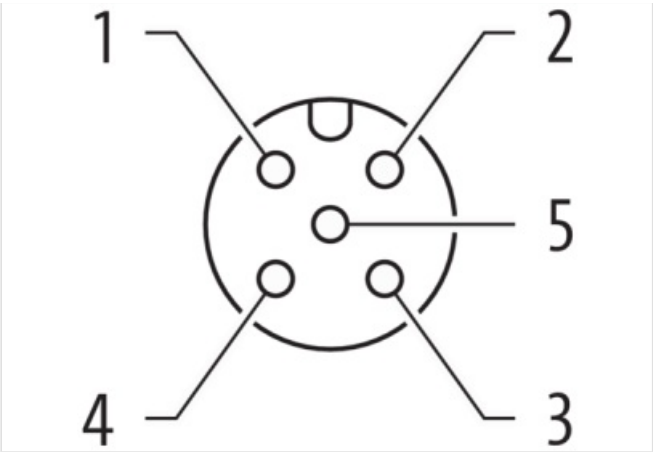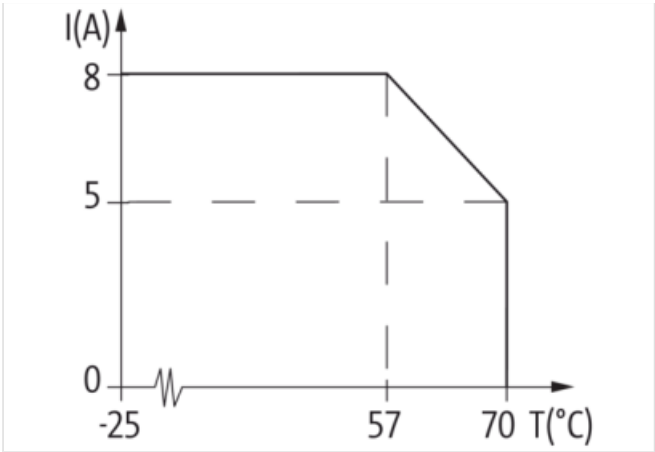

Product may differ from Image



Header	
Material short text	MVP12N-MK4V-XA
Commercial data	
URL Webshop	https://shop.murrelektronik.com/8000-84402-0000000
GTIN	4048879056069
ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
customs tariff number	85366990
EAN	4048879056069
Packaging unit	1
Electrical data Supply	
Operating voltage AC	125 V
Operating voltage DC	125 V
Current operating per contact max.	4 A
Total current max.	8 A
Device protection Electrical	

Degree of protection (EN IEC 60529) IP67, IP65

Device protection | Media

Flame resistance flame retardant

Mechanical data | Material data

Material housing Plastic

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 70 °C

Connection type 2

Family construction form Cap

No. of poles 9

Family construction form M12

No. of poles 4

Coding A

Gender female

Color contact carrier black

PIN 1 +

PIN 2 n.c.

PIN 3 -

PIN 4 NO S 1

PIN 5 PE