

CAP FOR EXACT8, SHORT, WITH 12-POLE SPRING TERM.

Without homerun-cable

Art.No.: 8000-84949-0000000

Weight: 0.035

Country of origin: CZ

Model designation: MVP8N-ZHFS

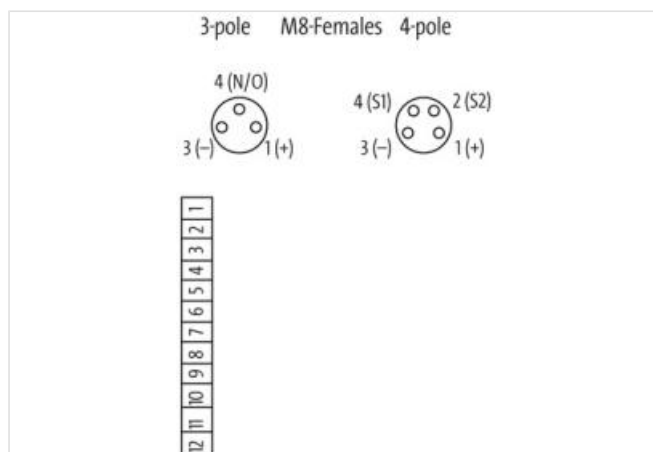
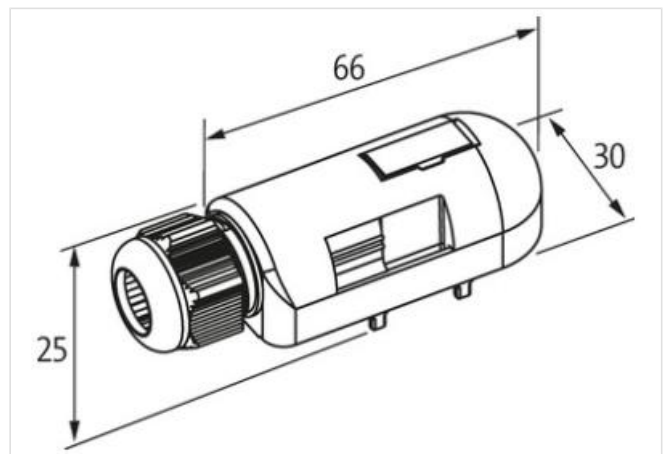
Connection cap short

Spring clamp terminals, 12-pole

Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0

27143423

ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440111
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
customs tariff number	85369010
customs tariff number	85366990
customs tariff number	85369010
GTIN	4048879055321
GTIN	4048879055321
GTIN	4048879055321
Packaging unit	1
Packaging unit	1
Packaging unit	1

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

Connection type 2

Family construction form	Cap
No. of poles	12
Family construction form	M8
Gender	female
Color contact carrier	black
Coding	A
No. of poles	3