

EXACT8, 8XM8, 3 POLE BASIC HOUSING

Without con. cable

Art.No.: 8000-88000-0000000

Weight: 0.122 kg

Country of origin: DE

Model designation: MVP8N-MK8D

8-way, 3-pole




Inline face or side mounting

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

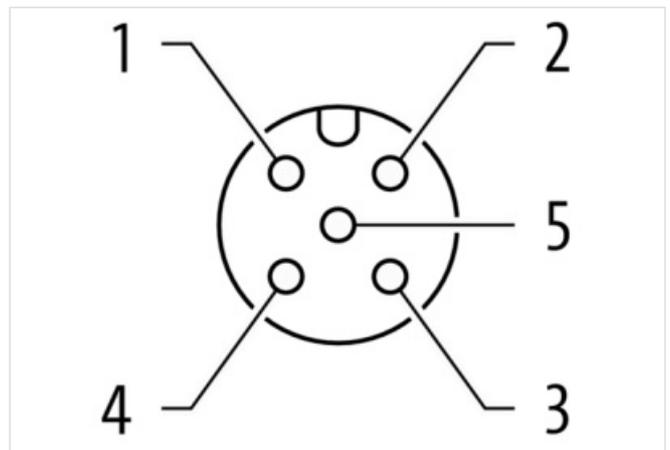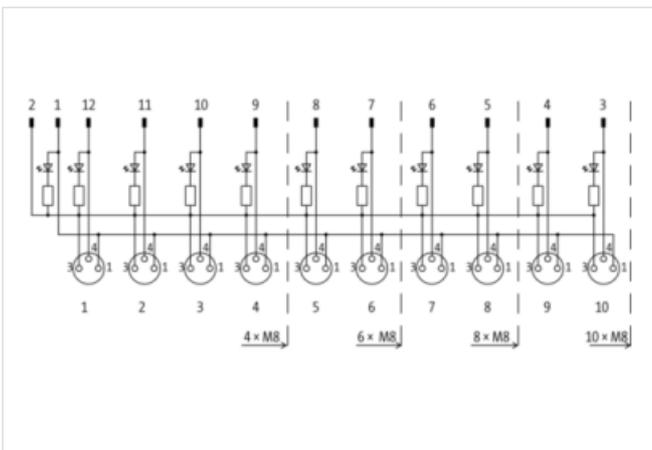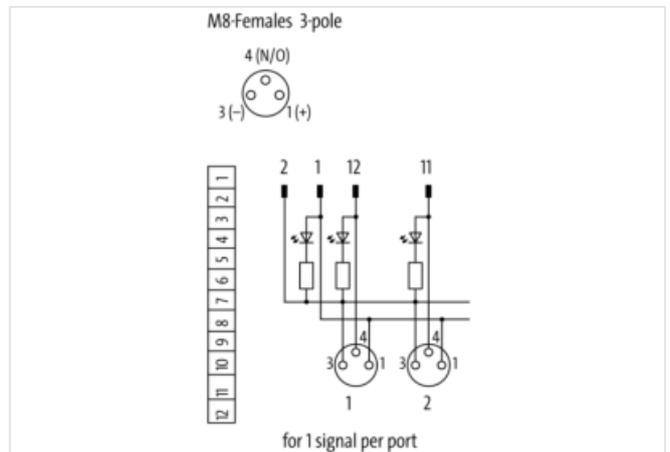

Product may differ from Image



Commercial data

| | |
|-----------------------|---|
| URL Webshop | https://shop.murrelektronik.com/8000-88000-0000000 |
| GTIN | 4048879054805 |
| Customs tariff number | 85366990 |

| | |
|-----------------------|---------------|
| ECLASS-6.0 | 27143423 |
| ECLASS-6.1 | 27279219 |
| ECLASS-7.0 | 27279219 |
| ECLASS-7.1 | 27279219 |
| ECLASS-8.0 | 27279219 |
| ECLASS-8.1 | 27279219 |
| ECLASS-9.0 | 27440111 |
| ECLASS-10.0.1 | 27440111 |
| ECLASS-10.1 | 27440111 |
| ECLASS-11.0 | 27440111 |
| ECLASS-11.1 | 27440111 |
| ECLASS-12.0 | 27440111 |
| ECLASS-13.0 | 27440111 |
| ECLASS-14.0 | 27440111 |
| ETIM-5.0 | EC002585 |
| ETIM-6.0 | EC002585 |
| ETIM-7.0 | EC002585 |
| ETIM-8.0 | EC002585 |
| customs tariff number | 85366990 |
| EAN | 4048879054805 |
| Packaging unit | 1 |

Electrical data | Supply

| | |
|------------------------------------|------|
| Operating voltage DC | 24 V |
| Current operating per contact max. | 2 A |
| Total current max. | 8 A |

Device protection | Electrical

| | |
|-------------------------------------|------------|
| Degree of protection (EN IEC 60529) | IP67, IP65 |
|-------------------------------------|------------|

Environmental characteristics | Climatic

| | |
|--|----------------------------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C |
| Additional condition temperature range | depending on cable quality |

Connection type 2

| | |
|--------------------------|--------|
| Family construction form | Cap |
| No. of poles | 12 |
| Family construction form | M8 |
| No. of poles | 3 |
| Coding | A |
| Gender | female |
| Color contact carrier | black |
| PIN 1 | + |
| PIN 3 | - |
| PIN 4 | S |