

EXACT8, 8XM8, 3 POLE BASIC HOUSING

Without con. cable

Art.No.: 8000-88000-0000000

Weight: 0.122

Country of origin: DE

Model designation: MVP8N-MK8D

8-way, 3-pole


Inline face or side mounting

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product**Illustration**

M8-Females 3-pole

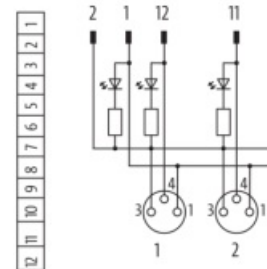

for 1 signal per port

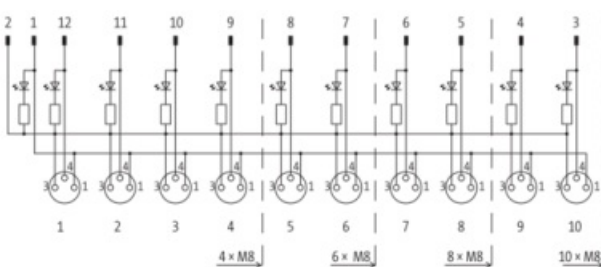

Product may differ from Image

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/8000-88000-0000000>

GTIN

4048879054805

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
EAN	4048879054805
Electrical data Supply	
Operating voltage DC	24 V
Current operating per contact max.	2 A
Total current max.	8 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67, IP65
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C
Additional condition temperature range	depending on cable quality
Connection type 2	
Family construction form	Cap
No. of poles	12
Family construction form	M8
No. of poles	3
Coding	A
Gender	female
Color contact carrier	black
PIN 1	+
PIN 3	-
PIN 4	S