

**EXACT12, 8XM12, 4 POLE**

Conn.M12 12-pole

Art.No.: 8000-88460-0000000

Weight: 0.150 kg

Country of origin: DE

Model designation: MVP12N-GS8V

8-way

4-pole (port 3...8)

5-pole (port 1+2)




M12 plug connection, 12-pole



with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.

[Link to Product](#)

**Illustration**

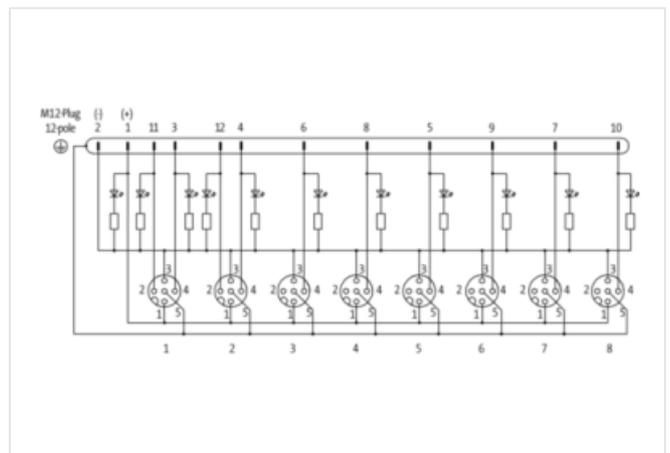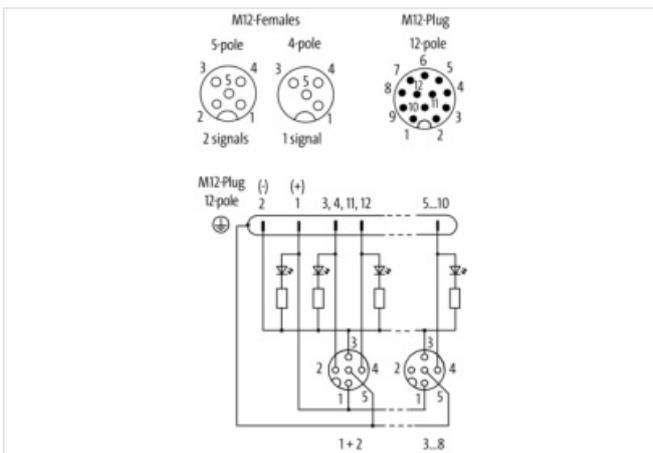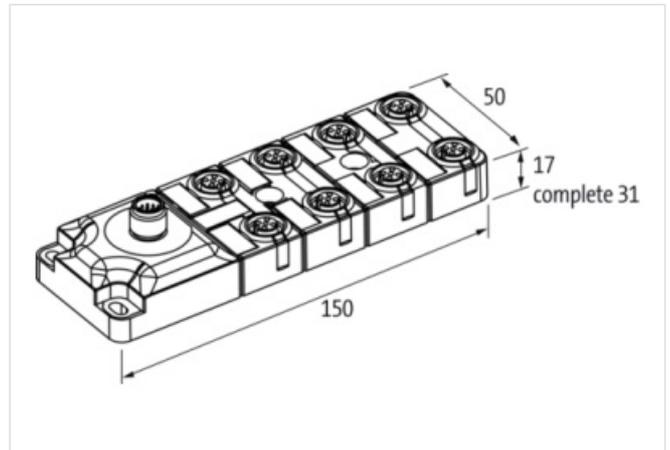

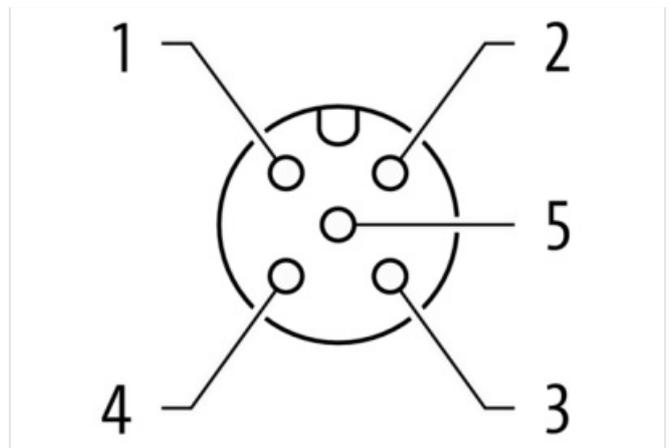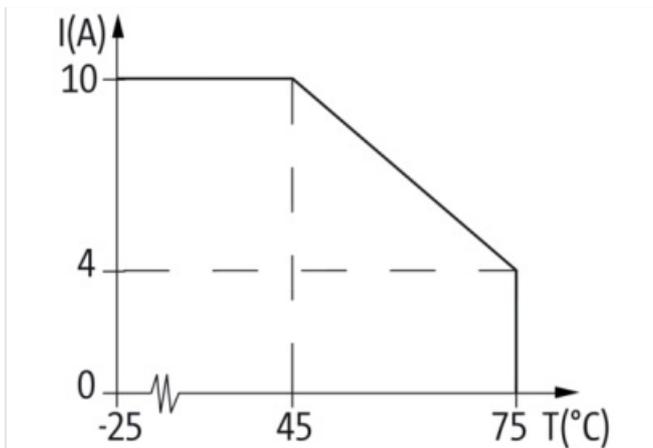

Product may differ from Image

**Commercial data**

URL Webshop	<a href="https://shop.murrelektronik.com/8000-88460-0000000">https://shop.murrelektronik.com/8000-88460-0000000</a>
GTIN	4048879313155
Customs tariff number	85366990
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
customs tariff number	85366990
EAN	4048879313155
Packaging unit	1

**Electrical data | Supply**

Operating voltage DC	24 V
Current operating per contact max.	1,5 A
Total current max.	1,5 A

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP67, IP65
-------------------------------------	------------

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

housing	Plastic
---------	---------

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C

**Connection type 2**

Family construction form	M12
No. of poles	4
Coding	A
Gender	female
Color contact carrier	black
PIN 1	+
PIN 2	n.c.
PIN 3	-
PIN 4	NO S 1
PIN 5	PE
Family construction form	M12
No. of poles	12
Coding	A
Gender	male
Color contact carrier	black
PIN 1	+
PIN 2	-