

**EXACT12, 8XM12, 4 POLE**

Conn.M12 12-pole

Art.No.: 8000-88460-0000000

Weight: 0.15

Country of origin: DE

Model designation: MVP12N-GS8V

8-way

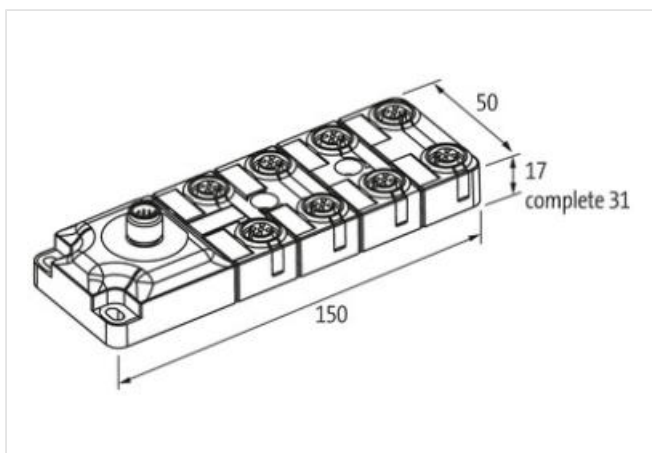
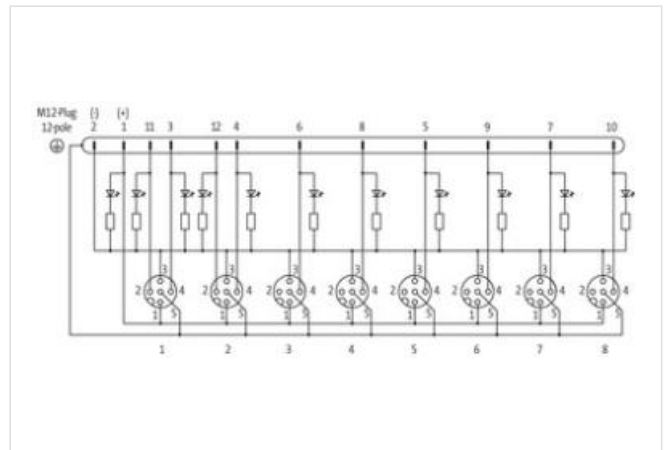
4-pole (port 3...8)

5-pole (port 1+2)

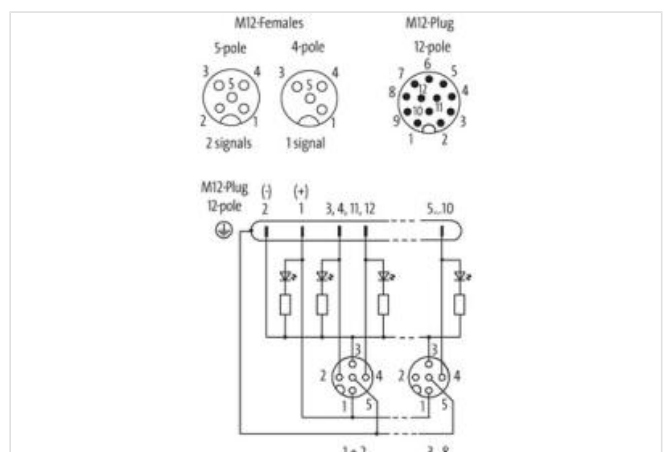
M12 plug connection, 12-pole

with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

|   |                 |
|---|-----------------|
| ECLASS-6.0                                      | 27143423        |
| ECLASS-6.1                                      | 27279219        |
| ECLASS-7.0                                      | 27279219        |
| ECLASS-8.0                                      | 27279219        |
| ECLASS-9.0                                      | 27440111        |
| ECLASS-10.1                                     | 27440111        |
| ECLASS-11.1                                     | 27440111        |
| ECLASS-12.0                                     | 27440111        |
| ETIM-5.0  | EC002585        |
| customs tariff number                           | 85369010        |
| customs tariff number                           | 85366990        |
| customs tariff number                           | 85369010        |
| GTIN  | 4048879313155   |
| GTIN  | 4048879313155   |
| GTIN  | 4048879313155   |
| Packaging unit                                  | 1               |
| Packaging unit                                  | 1               |
| Packaging unit                                  | 1               |
| <b>Electrical data   Supply</b>                 |                 |
| Operating voltage DC                            | 24 V            |
| Current operating per contact max.              | 1,5 A           |
| Total current max.                              | 1,5 A           |
| <b>Device protection   Electrical</b>           |                 |
| Degree of protection (EN IEC 60529)             | IP65, IP67      |
| <b>Device protection   Media</b>                |                 |
| Flame resistance                                | flame retardant |
| <b>Mechanical data   Material data</b>          |                 |
| Material housing                                | Plastic         |
| <b>Environmental characteristics   Climatic</b> |                 |
| Operating temperature min.                      | -20 °C          |
| Operating temperature max.                      | 70 °C           |
| <b>Connection type 2</b>                        |                 |
| Family construction form                        | M12             |
| Gender  | female          |
| Color contact carrier                           | black           |
| Coding  | A               |
| No. of poles                                    | 4               |
| PIN 1   | +               |
| PIN 2   | n.c.            |
| PIN 3   | -               |
| PIN 4   | NO S 1          |
| PIN 5   | PE              |
| Family construction form                        | M12             |
| Gender  | male            |
| Color contact carrier                           | black           |
| Coding  | A               |
| No. of poles                                    | 12              |
| PIN 1   | +               |
| PIN 2   | -               |