

EXACT12, 8XM12, 5-POLE, BASIC HOUSING, NPN-LED'S

Without homerun-cable

Art.No.: 8000-88501-0000000

Weight: 0.127

Country of origin: DE

Model designation: MVP12N-MK8F-NP

8-way, 5-pole

Form NPN



Screw plug-in terminals

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

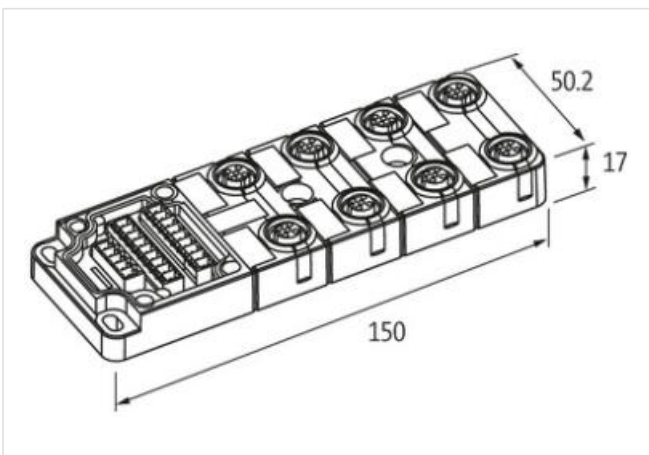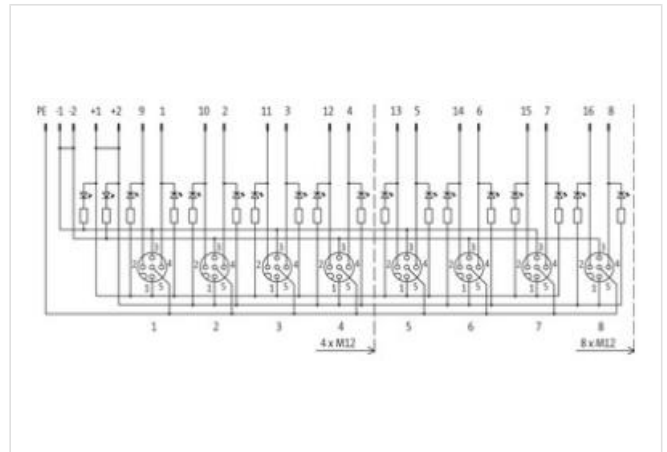

Product may differ from Image

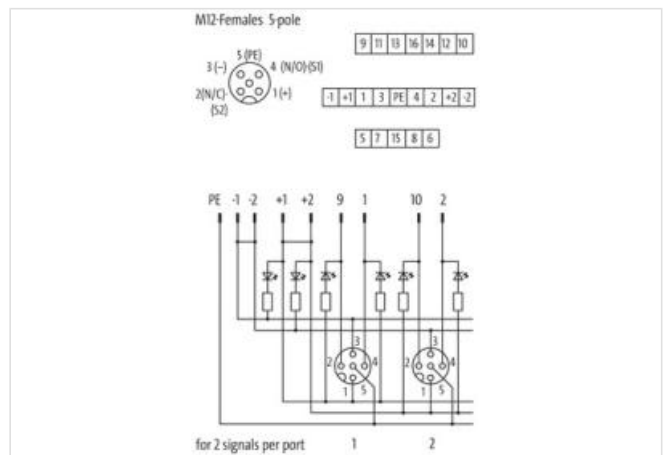

Commercial data

ECLASS-6.0

27143423

ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440111
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
customs tariff number	85369010
customs tariff number	85369010
customs tariff number	85366990
GTIN	4048879054058
GTIN	4048879054058
GTIN	4048879054058
Packaging unit	1
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current max.	8 A

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67
-------------------------------------	------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C