

EXACT12, 8XM12, 5-POLE, BASIC HOUSING, NPN-LED'S

Without homerun-cable

Art.No.: 8000-88501-0000000

Weight: 0.127

Country of origin: DE

Model designation: MVP12N-MK8F-NP

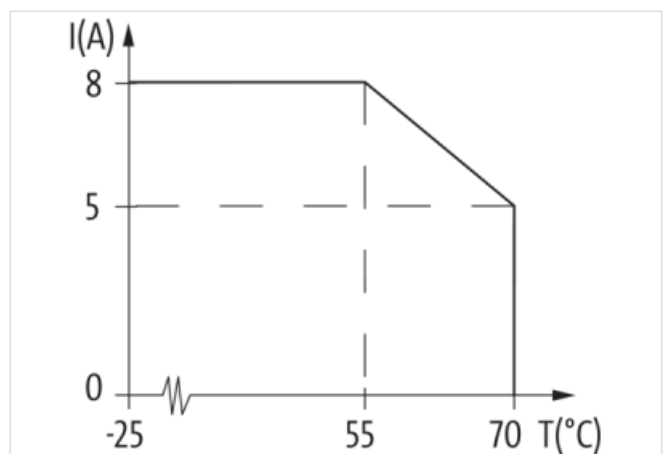
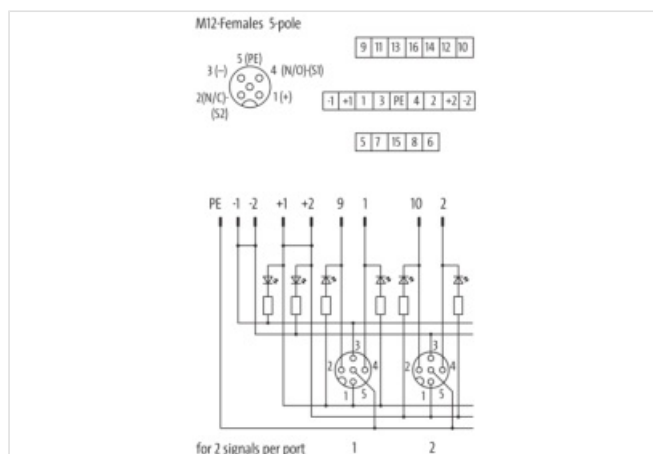
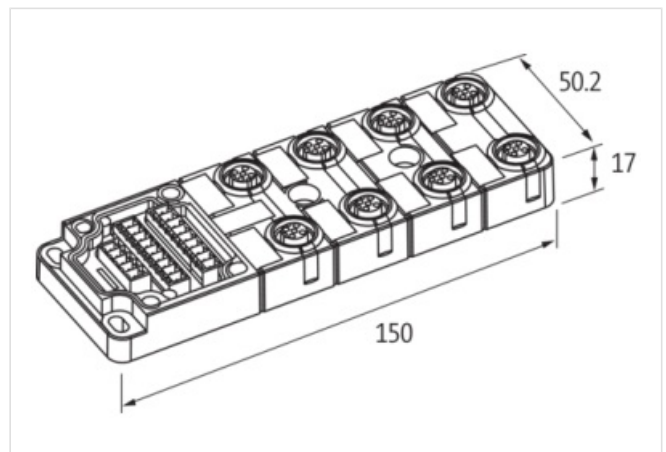
8-way, 5-pole

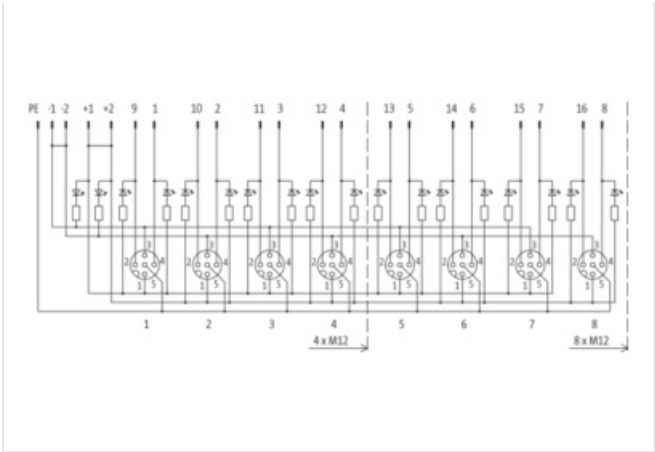
Form NPN

Screw plug-in terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**



Product may differ from Image



| Commercial data | |
|--|---|
| URL Webshop | https://shop.murrelektronik.com/8000-88501-0000000 |
| GTIN | 4048879054058 |
| ECLASS-6.0 | 27143423 |
| ECLASS-6.1 | 27279219 |
| ECLASS-7.0 | 27279219 |
| ECLASS-7.1 | 27279219 |
| ECLASS-8.0 | 27279219 |
| ECLASS-8.1 | 27279219 |
| ECLASS-9.0 | 27440111 |
| ECLASS-10.0.1 | 27440111 |
| ECLASS-10.1 | 27440111 |
| ECLASS-11.0 | 27440111 |
| ECLASS-11.1 | 27440111 |
| ECLASS-12.0 | 27440111 |
| ECLASS-13.0 | 27440111 |
| ECLASS-14.0 | 27440111 |
| ETIM-5.0 | EC002585 |
| ETIM-6.0 | EC002585 |
| ETIM-7.0 | EC002585 |
| ETIM-8.0 | EC002585 |
| EAN | 4048879054058 |
| Electrical data Supply | |
| Operating voltage DC | 24 V |
| Current operating per contact max. | 4 A |
| Total current max. | 8 A |
| Device protection Electrical | |
| Degree of protection (EN IEC 60529) | IP67, IP65 |
| Device protection Media | |
| Flame resistance | flame retardant |
| Mechanical data Material data | |
| Material housing | Plastic |
| Environmental characteristics Climatic | |

| | |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C |
