

EXACT12, 8XM12, 5-POLE, BASIC HOUSING, NPN-LED'S

Without homerun-cable

Art.No.: 8000-88501-0000000

Weight: 0.127 kg

Country of origin: DE

Model designation: MVP12N-MK8F-NP

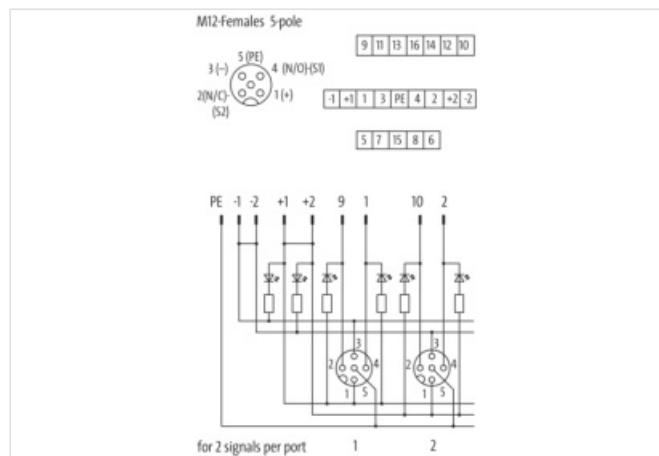
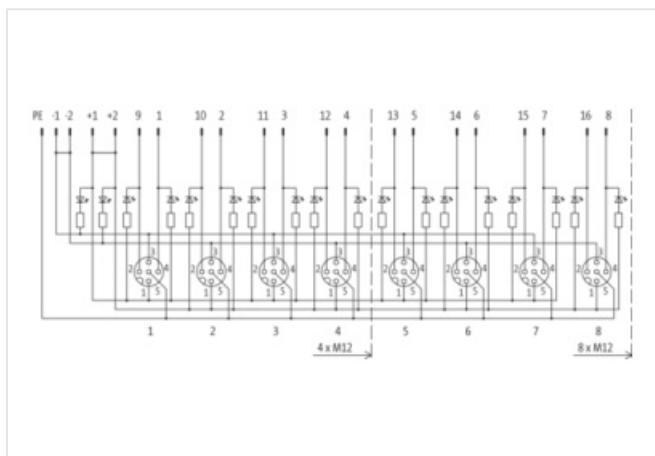
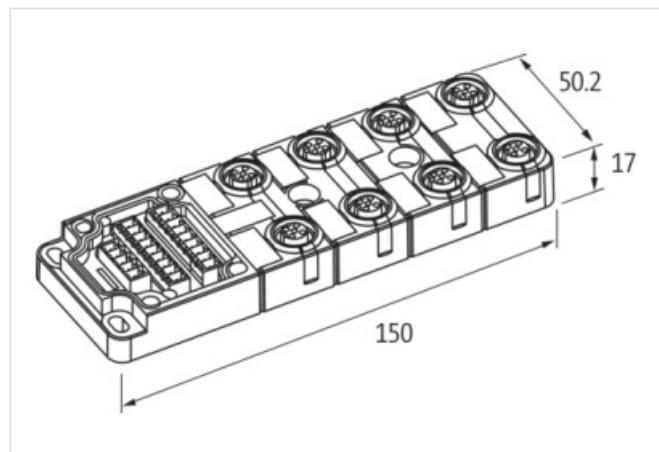
8-way, 5-pole

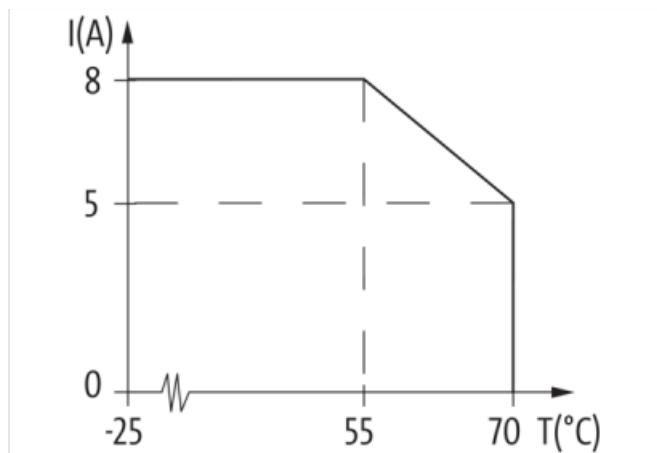
Form NPN

Screw plug-in terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)
Illustration




Product may differ from Image



Header

Material short text MVP12N-MK8F-NP

Commercial data

URL Webshop	https://shop.murrelektronik.com/8000-88501-0000000
GTIN	4048879054058
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
customs tariff number	85366990
EAN	4048879054058
Packaging unit	1
customs tariff number	85366990
EAN	4048879054058
Packaging unit	1

Electrical data | Supply

Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current max.	8 A

Device protection | Electrical

Degree of protection (EN IEC 60529) IP67, IP65

Device protection | Media

Flame resistance flame retardant

Mechanical data | Material data

Material housing Plastic

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 70 °C