

CAP BIG WITH PLUG. SPRING TERM. 21-POLE



For use with 4-,6-,8-way d-box M12 5-pole

Art.No.: 8000-88549-0000000
Weight: 0.048 kg
Country of origin: CZ
Model designation: MVZ12-HFK21H MVMX 21P.

Cap for 4-, 6-, and 8-way distribution box, 5-pole
Spring clamp plug-in terminals
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

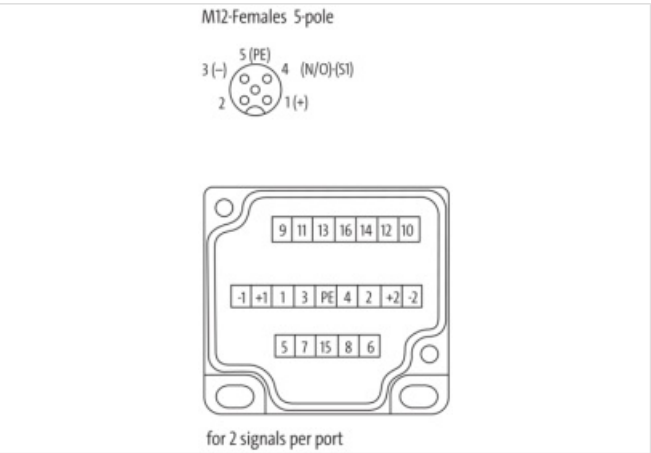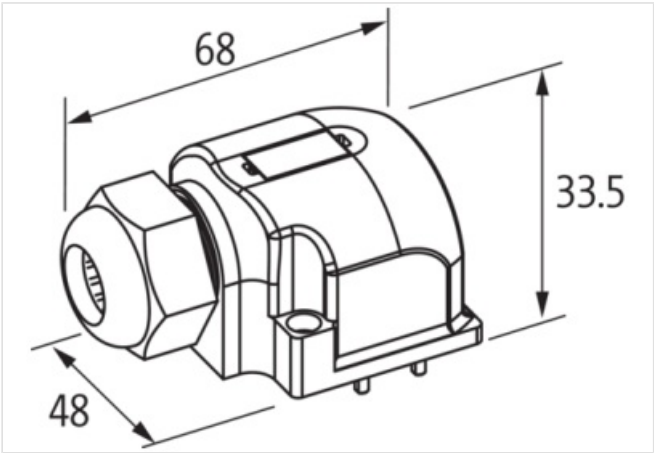

Product may differ from Image



Header

Material short text MVZ12-HFK21H MVMX 21P.

Commercial data

URL Webshop	https://shop.murrelektronik.com/8000-88549-0000000
GTIN	4048879300032
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
customs tariff number	85366990
EAN	4048879300032
Packaging unit	1

Electrical data | Supply

Total current max.	8 A
--------------------	-----

Installation

Connection cross section max.	1,5 mm ²
AWG number max.	16

Installation | Connection

Connection	Spring clamp terminals FK
------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

Connection type 1

Family construction form	Cap
No. of poles	21