

SUPPRESSOR FOR CONTACTORS

RC, 230 VAC/DC, 20 VA/W


230 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

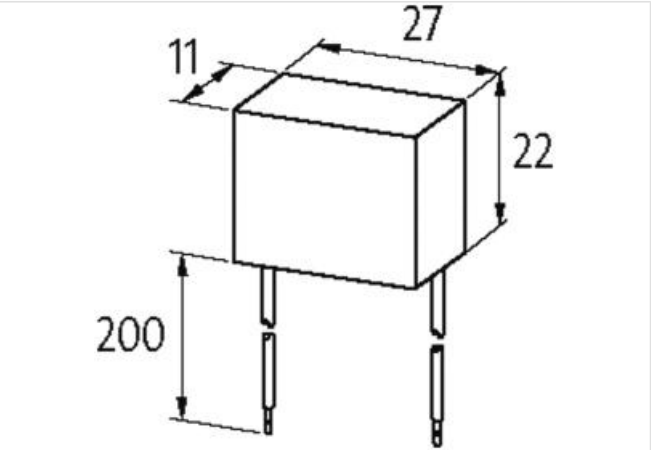

Product may differ from Image



| Commercial data | |
|-----------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-9.0 | 27371013 |
| ECLASS-10.1 | 27371013 |

| | |
|---|---------------------------|
| ECLASS-11.1 | 27371013 |
| ECLASS-12.0 | 27371013 |
| ETIM-5.0 | EC002498 |
| customs tariff number | 85363010 |
| GTIN | 4048879020343 |
| Packaging unit | 1 |
| Compatibility Compatible with | |
| Appropriate contactors | universal |
| Electrical data | |
| Damping factor | 1.5× UN |
| Holding power max. | 20 W |
| Electrical data Input | |
| Input voltage AC min. | 110 V |
| Input voltage AC max. | 253 V |
| Input voltage DC min. | 110 V |
| Input voltage DC max. | 253 V |
| Installation Connection | |
| Connection information | flexible connection wires |
| Device protection Media | |
| Flame resistance | flame retardant |
| Mechanical data Material data | |
| Combustibility class housing (UL94) | V-0 |
| Material housing | Plastic |
| Mechanical data Mounting data | |
| Height | 22 mm |
| Width | 27 mm |
| Depth | 11 mm |
| Environmental characteristics Climatic | |
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C |