


MA5I67 INSTALLATION TECHNOLOGY

Distribution 1x profile- to 3x profile cable


MA5I67 distribution boxes  
1× on 3× profile cable

Link to Product

Illustration

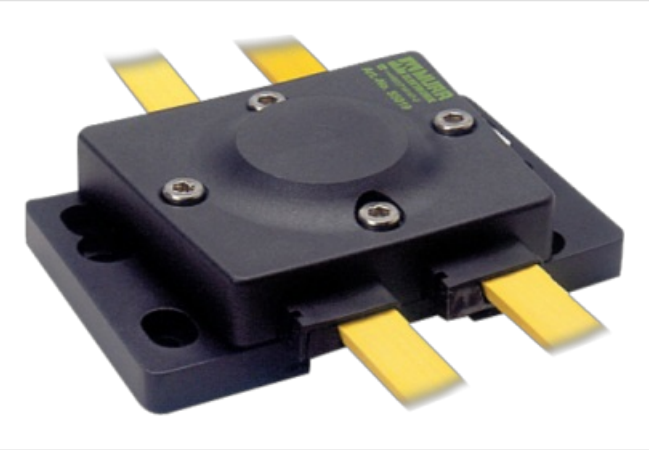

Product may differ from Image

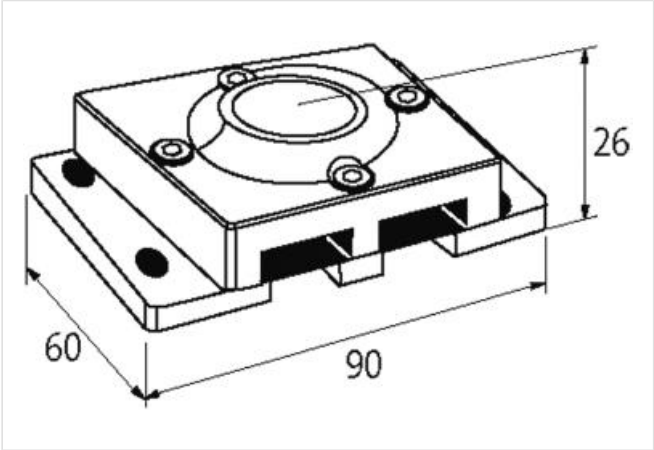

Commercial data	
ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
customs tariff number	85369010
GTIN	4048879052177
Packaging unit	1
Electrical data   Supply	
Operating voltage DC max.	36 V
Total current max.	8 A
Device protection   Electrical	
Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V
Mechanical data   Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm

Width	74 mm
Depth	26 mm
Environmental characteristics   Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 60664-1