



MASI67 INSTALLATION TECHNOLOGY

Converter 2x profile cable to 7/8" female

MASI67 converter
2x profile cable to 7/8" (female)
Connection cables are in the online shop under "Connection Technology".

[Link to Product](#)

Illustration

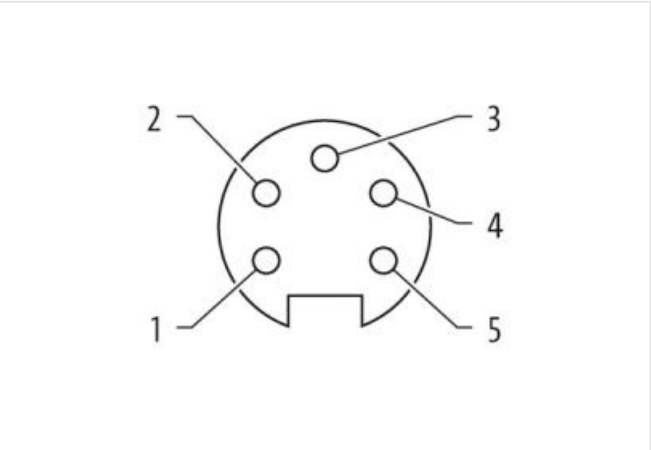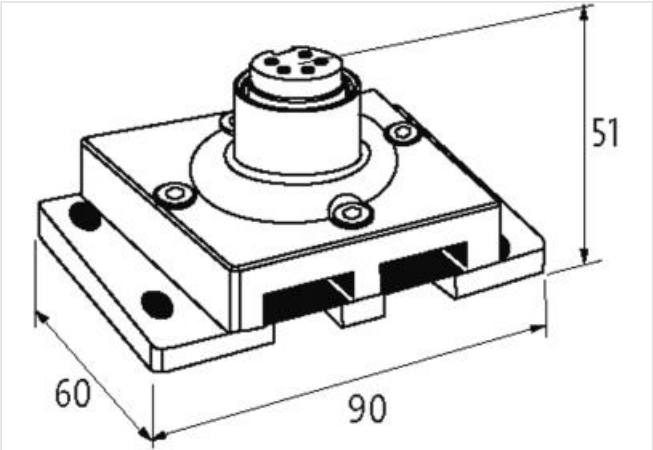

Product may differ from Image



Commercial data	
ECLASS-6.0	27400209
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111

ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001583
customs tariff number	85369010
GTIN	4048879052160
Packaging unit	1
Electrical data Supply	
Operating voltage DC max.	36 V
Total current max.	8 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Insulation strength ASI/Power	200 V
Mechanical data Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	90 mm
Width	74 mm
Depth	52 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 60664-1
Connection type 1	
Family construction form	7/8"
Gender	female
Color contact carrier	black
No. of poles	5
PIN 1	AS-i +
PIN 2	AS-i -
PIN 3	n.c.
PIN 4	24 V DC
PIN 5	0 V