




MASI20 INSTALLATION TECHNOLOGY

Distributor AS-I and extern power, 3 potentials

5 ports, universal
3 potentials
without plug terminals

[Link to Product](#)

Illustration

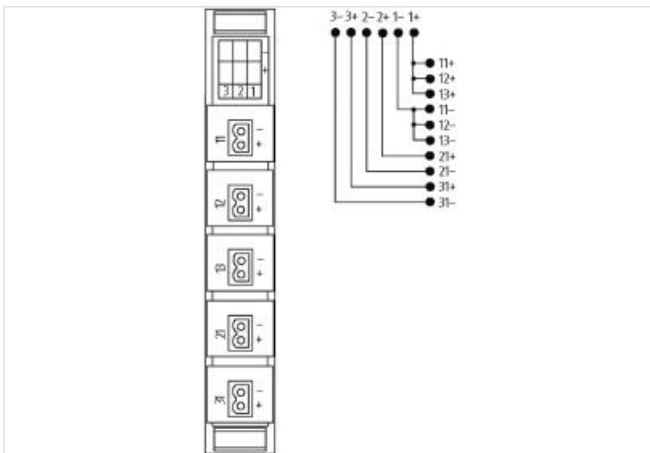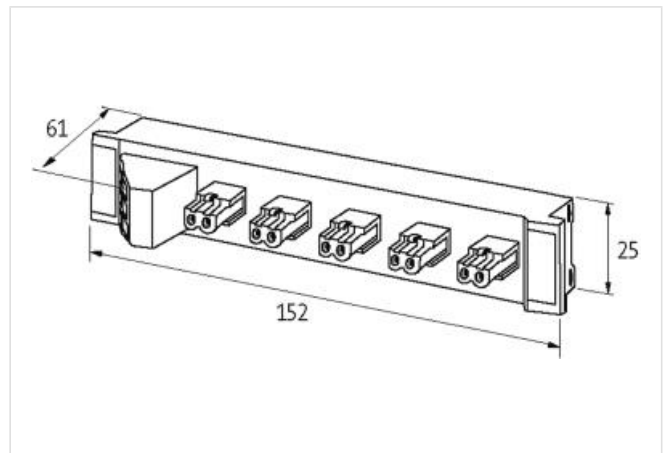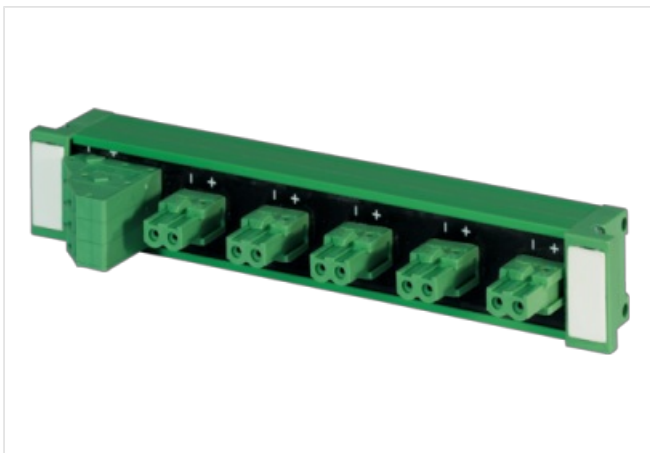

Product may differ from Image



Classifications

ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111

ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC001596

Technical Data

Operating voltage	max. 36 V DC
Current per connection	max. 8 A
Total current	max. 12 A

General data

Mounting method	DIN-rail mountable (EN 60715)
Temperature range	-20...+70 °C
Test isolation voltage	AS-Interface/Power 200 V, Power/Power 50 V (EN 60664-1)
Protection	IP20
Connection	Screw terminal: single wire (0.2...2.5 mm ²), stranded wire (0.2...1.5 mm ²)
Dimensions H×W×D	43×25×142 mm

Commercial data

customs tariff number	85366990
GTIN	4048879050487
Packaging unit	1