



IN: 230/400+/-15VAC OUT: :24V/15ADC

Link to Product

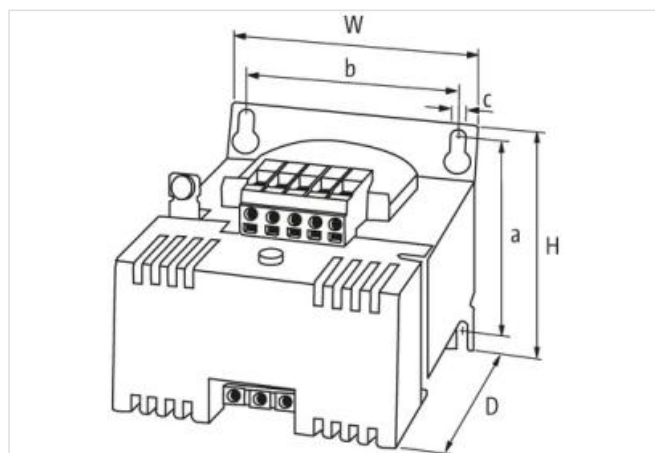

Product may differ from Image

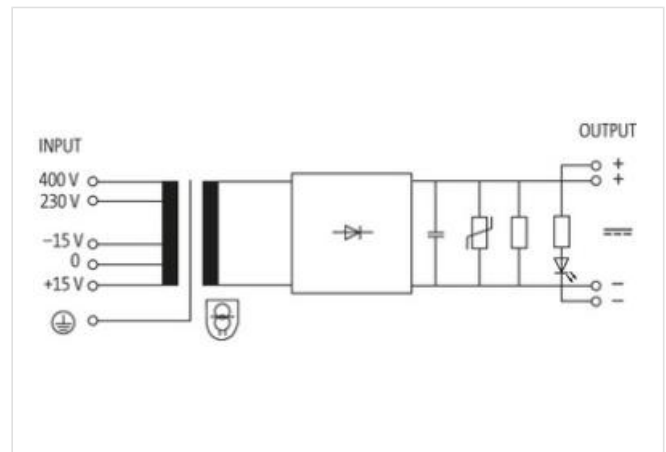

| | |
|-------------|----------|
| ECLASS-6.0 | 27049002 |
| ECLASS-6.1 | 27049002 |
| ECLASS-7.0 | 27049002 |
| ECLASS-8.0 | 27049002 |
| ECLASS-9.0 | 27040701 |
| ECLASS-10.1 | 27040701 |
| ECLASS-11.1 | 27040701 |
| ECLASS-12.0 | 27040701 |

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

| | |
|---|-----------------------------------|
| ETIM-5.0 | EC002540 |
| customs tariff number | 85044095 |
| GTIN | 4048879080040 |
| Packaging unit | 1 |
| Electrical data | |
| Security level | SELV |
| Electrical data Supply | |
| Power frequency | 50 ... 60 Hz |
| Electrical data Input | |
| Fuse protection 1 primary side external | 4 A @230 V AC |
| Fuse protection 2 primary side external | 2,5 A @400 V AC |
| Characteristic back-up fuse | Inertia |
| Input voltage 1 AC | 230 V |
| Input voltage 1 AC min. | 195,5 V |
| Input voltage 1 AC max. | 264,5 V |
| Input voltage 2 AC | 400 V |
| Input voltage 2 AC min. | 340 V |
| Input voltage 2 AC max. | 460 V |
| Input current at input voltage 1 AC | 2,8 A |
| Input current at input voltage 2 AC | 1,65 A |
| Electrical data Output | |
| Output suppression | LED, Screening capacitor, VDR |
| Output voltage DC | 24 V |
| Output voltage adjustable | no |
| Output current max. | 18 A |
| Ripple max. | 5 % |
| Mechanical data Mounting data | |
| Suitable for mounting type | Schlüssellochauhängung |
| Mounting dimension a | 126 mm |
| Mounting dimension b | 104 mm |
| Mounting dimension c | 6,6 mm |
| Height | 138,5 mm |
| Width | 135 mm |
| Depth | 181,5 mm |
| Environmental characteristics Climatic | |
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C |
| Derating from | 40 °C |
| Conformity | |
| Product standard | EN 61558-2-6, EN 62041 category I |
| EMC | EN 55011 B, EN 61000-3-2 |
| Connection type 3 | |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | metallic |
| No. of poles | 1 |
| PIN 1 | PE |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |

| | |
|--------------------------|--------------------|
| Color contact carrier | green |
| No. of poles | 4 |
| PIN 1 | + |
| PIN 2 | + |
| PIN 3 | - |
| PIN 4 | - |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | green |
| No. of poles | 5 |
| PIN 1 | + 15 V |
| PIN 3 | - 15 V |
| PIN 4 | 230 V |
| PIN 5 | 400 V |