

MEN POWER SUPPLY 1/2-PHASE, SMOOTHED

IN: 230/400+/-15VAC OUT: :24V/15ADC



Current: 15 A

Output rating: 360 W

This power supply units meet the (EN 61000-3-2) standard for harmonic current.

Link to Product

Illustration

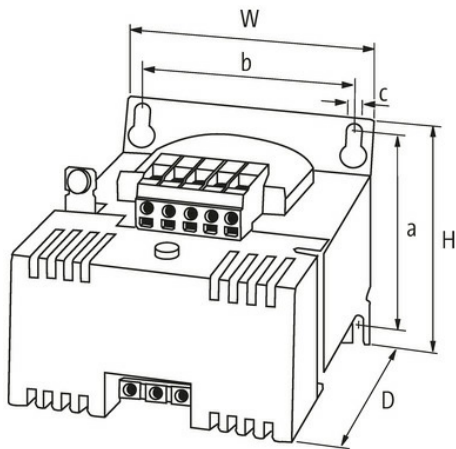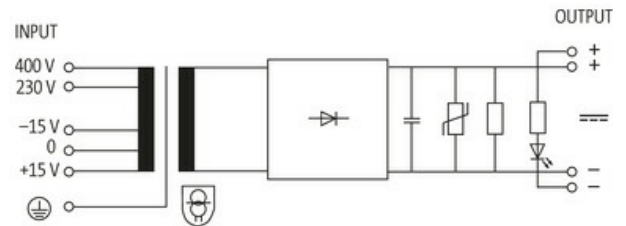

Product may differ from Image



General data

Standards	EN 61558-2-6, EN 62041 category I, EN 55011 B, EN 61000-3-2
Mounting method	Key-hole mounting
Temperature range	-20...+60 °C, no condensation
Fixing centers a×b×c	126×104×6.5 mm
Dimensions H×W×D	138.5×135×181.5 mm

Output

The information in this brochure has been compiled with the utmost care. Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 01/22

Output voltage	24 V DC (SELV)
Output current (Ta 60/40 °C)	max. 15 A (230 V AC); 18 A (400 V AC)
Output suppression	LED, VDR and smoothing capacitor
Ripple	max. 5% eff/rms

Input

Input voltage	230/400 ±15 V AC
Input fuse (external)	4 AT (230 V AC); 2.5 AT (400 V AC)
Input current	2.8 A (230 V AC); 1.65 A (400 V AC)
Frequency	50...60 Hz

Commercial data

country of origin	CZ
customs tariff number	85044090
EAN	4048879080040
eClass	27049002
Packaging unit	1.000