
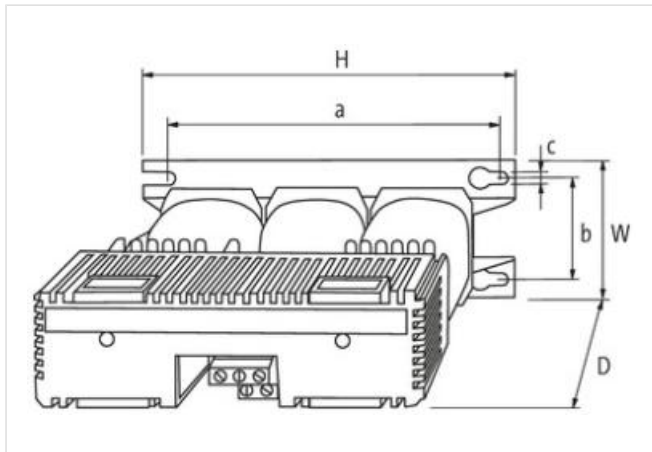


IN: 400VAC+/- 5% OUT: 24V/5ADC

Output rating: 120 W

This power supply units meet the (EN 61000-3-2) standard for harmonic current.
Any mounting position on vertical wall, condensation not permissible

Illustration

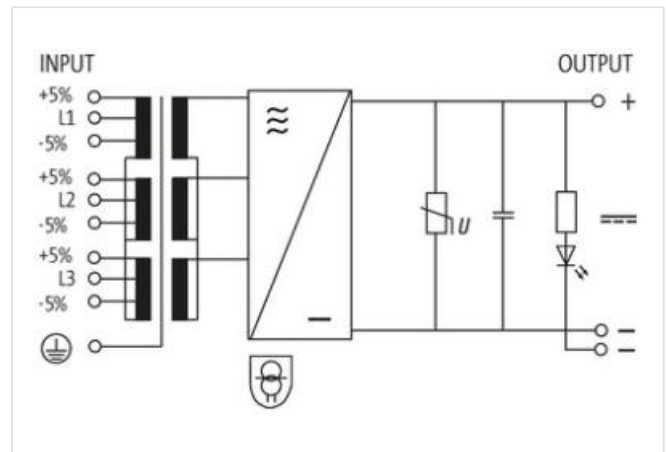

UK
CA

C  US
LISTED

C  US

C 

ECLASS-6.0	27049002
ECLASS-6.1	27049002
ECLASS-7.0	27049002
ECLASS-8.0	27049002
ECLASS-9.0	27040701
ECLASS-10.1	27040701

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

ECLASS-11.1	27040701
ECLASS-12.0	27040701
ETIM-5.0	EC002540
customs tariff number	85044095
GTIN	4048879079273
Packaging unit	1
Electrical data	
Security level	SELV
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Fuse protection 1 primary side external	0,4 A
Characteristic back-up fuse	Inertia
Input voltage AC	400 V
Input voltage AC min.	380 V
Input voltage AC max.	420 V
Current input AC	0,3 A
Phase number input	3
Efficiency	72 %
Electrical data Output	
Fuse protection secondary side external	5 A
Output suppression	LED, Screening capacitor, VDR
Output voltage DC	24 V
Output voltage adjustable	no
Output current max.	5 A
Characteristic secondary fuse	Inertia
Ripple max.	2 %
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochabhängung
Mounting dimension a	100 mm
Mounting dimension b	55 mm
Mounting dimension c	5 mm
Height	125 mm
Width	71 mm
Depth	153 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	55 °C
Conformity	
Product standard	EN 61558-2-6, EN 62041 category I
EMC	EN 55011 B, EN 61000-3-2