
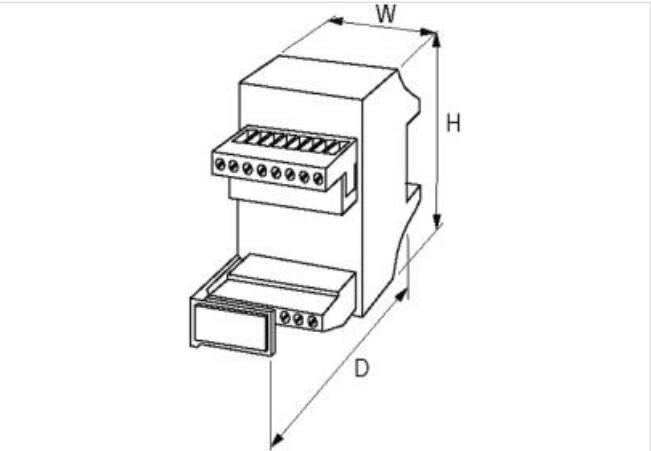


TRANSFER MODULE FOR DIN RAIL MOUNTING

23-pole  
for 1× 11- and 1× 12-pole spring clamp terminals  
pre-wired to push-in spring clamp terminals

[Link to Product](#)

Illustration

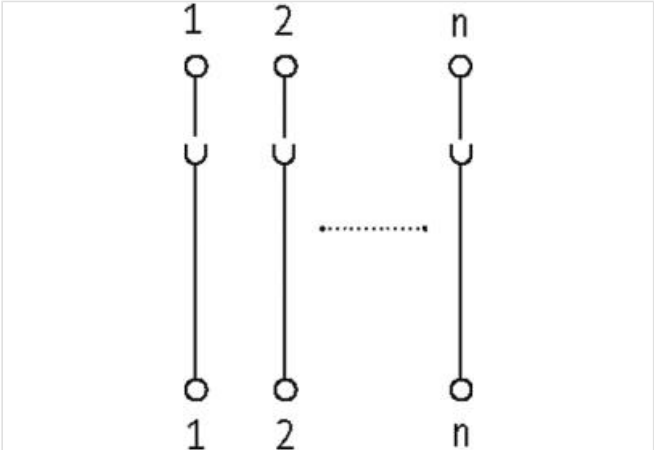

Product may differ from Image



Commercial data	
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152

ETIM-5.0	EC001583
customs tariff number	85369010
GTIN	4048879315692
Packaging unit	1
<b>Electrical data   Supply</b>	
Operating voltage DC	24 V
Operating current max.	8 A
<b>Installation</b>	
Connection cross-section solid max.	1 mm <sup>2</sup>
<b>Installation   Connection</b>	
Connection	Push-In spring clamp terminals
<b>Device protection   Electrical</b>	
Overvoltage category (EN 60664-1)	III
<b>Mechanical data   Mounting data</b>	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	45 mm
Depth	65 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C