


**MODLINK MSDD DBL COMBI INSERT GREAT BRITAIN**

1xRJ45 fem./fem. + RCD opening

- 1× Great Britain (BS)
- 1× RJ45, 8-pole metal, CAT5e (female/female)
- 1× FI cut-out

[Link to Product](#)

**Illustration**

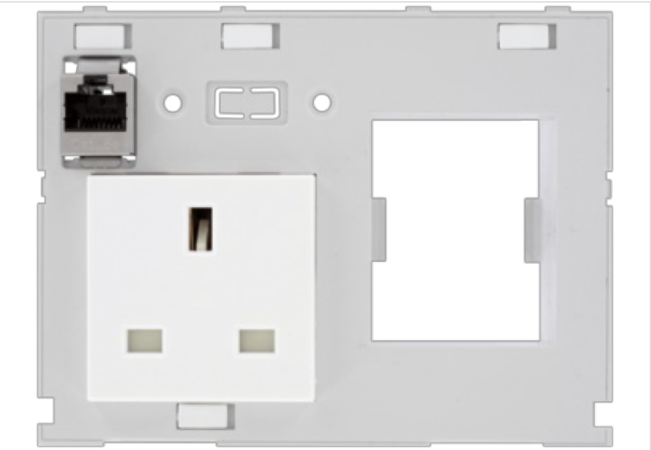

Product may differ from Image



Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879384506
Packaging unit	1
Mechanical data   Mounting data	
Height	88 mm
Width	116 mm
Depth	70 mm
Environmental characteristics   Climatic	
Storage temperature min.	5 °C
Storage temperature max.	40 °C
England	
Operating voltage AC	250 V

Operating current	13 A
No. of poles	2 + PE
Protection contact present	yes

**RJ45**

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector