


MODLINK MSDD DBL COMBI INSERT ITALY

1xRJ45 fem./fem. + RCD opening

- 1× Italy (CEI 23-16)
- 1× RJ45, 8-pole metal, CAT5e (female/female)
- 1× FI cut-out

Link to Product

Illustration

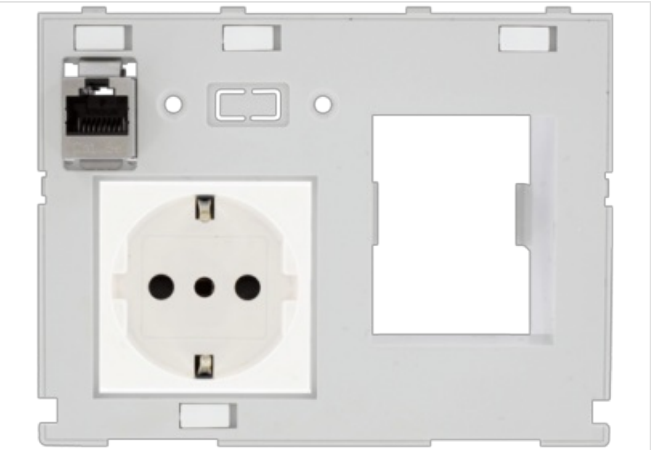

Product may differ from Image



Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879384605
Packaging unit	1
Mechanical data   Mounting data	
Height	88 mm
Width	116 mm
Depth	70 mm
Environmental characteristics   Climatic	
Storage temperature min.	-10 °C
Storage temperature max.	60 °C
Italy (CEI 23-16)	
Connection cross section max.	4 mm²

AWG number max.	12
Operating voltage AC	250 V
Operating current	16 A
Connection	Screw terminals SK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes

**RJ45**

Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector