


MODLINK MSDD DBL COMBI INSERT GERMANY YELLOW

1xRJ45+USB-A + RCD opening

- 1 × VDE yellow
- 1 × USB 3.0 (female/female) form A
- 1 × RJ45, 8-pole metal, CAT5e (female/female)
- 1 × FI cut-out

Link to Product

Illustration

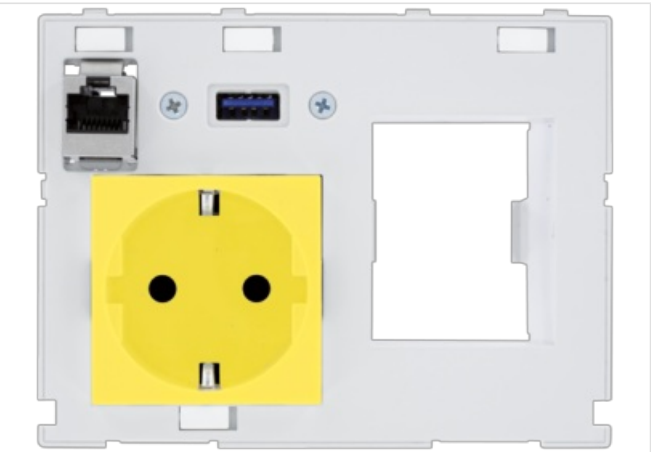

Product may differ from Image



| Commercial data | |
|--|---------------|
| ECLASS-6.0 | 27189234 |
| ECLASS-6.1 | 27189217 |
| ECLASS-7.0 | 27189217 |
| ECLASS-8.0 | 27189217 |
| ECLASS-9.0 | 27182806 |
| ECLASS-10.1 | 27182806 |
| ECLASS-11.1 | 27182806 |
| ECLASS-12.0 | 27182806 |
| ETIM-5.0 | EC002625 |
| customs tariff number | 85366990 |
| GTIN | 4048879654265 |
| Packaging unit | 1 |
| Mechanical data Mounting data | |
| Height | 88 mm |
| Width | 116 mm |
| Depth | 70 mm |
| Environmental characteristics Climatic | |
| Storage temperature min. | 5 °C |
| Storage temperature max. | 40 °C |
| Germany (VDE) | |

| | |
|-------------------------------|---------------------------|
| Connection cross section max. | 2,5 mm ² |
| AWG number max. | 14 |
| Operating voltage AC | 250 V |
| Operating current | 16 A |
| Connection | Spring clamp terminals FK |
| No. of poles | 2 + PE |
| Connections per pole | 2 |
| Protection contact present | yes |

USB

| | |
|---------------------------------------|-------------------|
| Operating voltage AC | 48 V |
| Operating voltage DC | 48 V |
| Operating voltage AC max. (UL-listed) | 30 V |
| Operating voltage DC max. (UL-listed) | 42,4 V |
| Operating current | 1,5 A |
| USB specification | 3.0 |
| Data transmission rate max. | 5000 MBit/s |
| Looking techniques | Snap-in connector |

RJ45

| | |
|---------------------------------------|-------------------|
| Operating voltage AC max. (UL-listed) | 30 V |
| Operating voltage DC max. (UL-listed) | 42,4 V |
| Current operating max. (UL) | 175 mA |
| Family construction form | RJ45 |
| Family type Back side | RJ45 |
| Cable category min. | Cat5e |
| Looking techniques | Snap-in connector |