


**MODLINK MSDD GENDER CHANGER**

USB-A 3.0 female/female

Pass-through  
1 × USB 3.0 (female/female) form A

[Link to Product](#)

Illustration

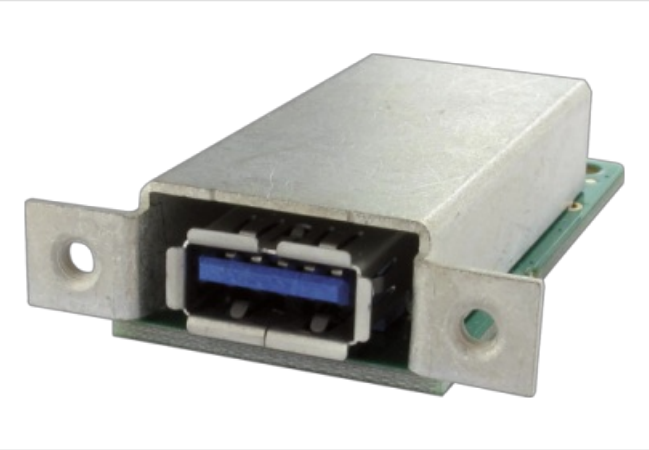

Product may differ from Image



Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27069202
ECLASS-7.0	27069202
ECLASS-8.0	27060324
ECLASS-9.0	27060324
ECLASS-10.1	27060324
ECLASS-11.1	27060324
ECLASS-12.0	27060324
ETIM-5.0	EC000830
customs tariff number	85366990
GTIN	4048879377706
Packaging unit	1
Electrical data   Supply	
Operating voltage DC	12 V
Operating current max.	2 A
Current operating max. (UL)	175 mA
Industrial communication	
USB specification	3.0
Data transmission rate max.	5000 MBit/s
Device protection	
Shielded	yes
Mechanical data   Mounting data	

Height	14 mm
Width	38 mm
Depth	58 mm